

Product Selector Guide




LED Vehicle Lighting

SIGNAL LAMPS

40/41 Series 4" Round


Fig. 1

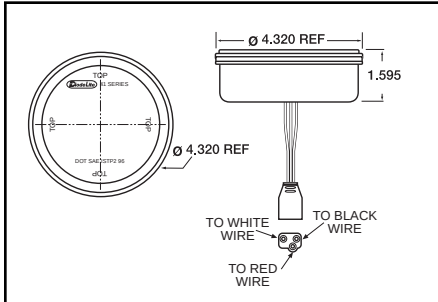

Grommet Mount
Fits industry standard grommets

40/41 Series 4" Round


Fig. 2

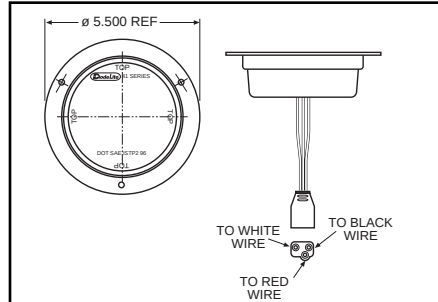

Flange Mount
Mounts in industry standard hole size
Available in black or white flange

70 Series 7" Round


Fig. 3

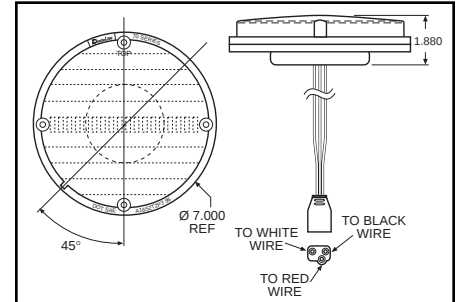

Largest LED lamp available
Enhances conspicuity

64 Series Oval


Fig. 4

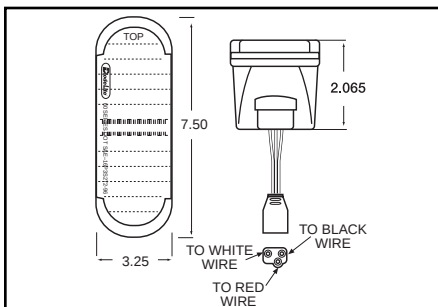

Vertical Grommet Mount
Fits industry standard grommets

62/65 Series Oval


Fig. 5

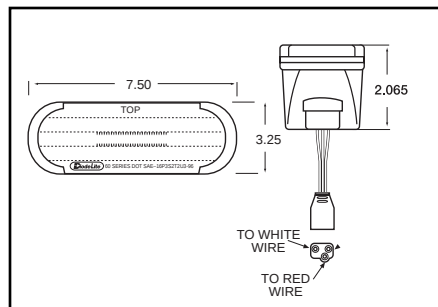

Horizontal Grommet Mount
Fits industry standard grommets
CHMSL is a 2 wire system
– Red, Hot
– White, Ground

64 Series Oval

Fig. 6

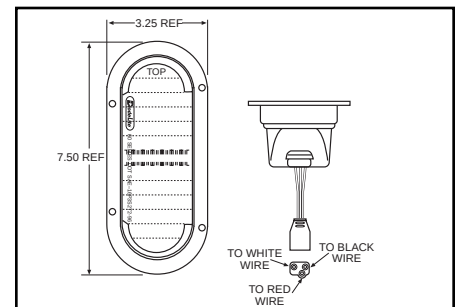


Vertical Flange Mount
Mounts in industry standard hole size
Available in black or white flange

Features:

- Meets FMVSS 108
- 9" **integral** 18 AWG wire leads
- Sealed polycarbonate assembly
- Potted design protects against moisture intrusion
- Standard termination is .180" male bullets or 3-way female connectors (shown)
- Available in alternative terminations
- Long life and reduced current draw
- 40 and 62 Series designed to meet FMVSS108 from 7V to 16V range

62/65 Series Oval

Fig. 7

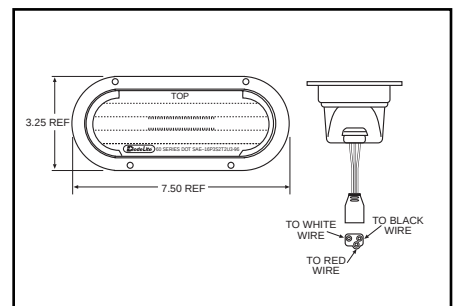

Horizontal Flange Mount
Mounts in industry standard hole size
Available in black or white flange
CHMSL is a 2 wire system
– Red, Hot
– White, Ground

Product Selector Guide



LED Vehicle Lighting

SIGNAL LAMPS

SIGNAL LAMPS		MOUNTING			CONNECTOR			
Part No.	Description	Grommet Mount	White Flange Mount	Black Flange Mount	.180" Male Bullets	3 way Female	Voltage Regulator	Figure
STOP/TAIL/TURN (RED)								
40071R	4 Inch Round	X			X		X	1
40091R	4 Inch Round		X		X		X	2
40101R	4 Inch Round			X	X		X	2
40141R	4 Inch Round		X			X	X	2
40151R	4 Inch Round	X				X	X	1
40161R	4 Inch Round			X		X	X	2
41071R	4 Inch Round	X			X			1
41101R	4 Inch Round			X	X			2
41141R	4 Inch Round		X			X		2
41151R	4 Inch Round	X				X		1
41161R	4 Inch Round			X		X		2
64071R	2 x 6 Oval Vertical	X			X			4
64151R	2 x 6 Oval Vertical	X				X		4
64161R	2 x 6 Oval Vertical			X		X		6
65071R	2 x 6 Oval Horizontal	X			X			5
65151R	2 x 6 Oval Horizontal	X				X		5
65161R	2 x 6 Oval Horizontal			X		X		7
70071R	7 Inch Round				X		X	3
CENTER HIGH MOUNTED STOP LAMP (CHMSL)								
62071R	2 x 6 Oval Horizontal CHMSL	X			X		X	5
62091R	2 x 6 Oval Horizontal CHMSL		X		X		X	7
62101R	2 x 6 Oval Horizontal CHMSL			X	X		X	7
REAR TURN (AMBER)								
41071A	4 Inch Round	X			X			1
41101A	4 Inch Round			X	X			2
41181A	4 Inch Round		X			X		2
41191A	4 Inch Round	X				X		1
41201A	4 Inch Round			X		X		2
70071A	7 Inch Round				X		X	3
ACCESSORIES								
94001A	40/41 SeriesMounting Grommet							
96001A	60/61/62 Series Mounting Grommet							