

[Find by Feature](#)
[Browse by Category](#)
[Share](#)
 [Search →](#)

Enter part number or keyword

[Search Results \(0\)](#)
[Search Options](#)

Select a product type to narrow your search:

Terminal ▼

Results with your selections: --

Blade size [mm] ▼

Terminal family ▼

Material ▼

Plating ▼

Gender ▼

Sealed ▼

Inside Ring Diameter [mm] ▼

Outside Ring Diameter [mm] ▼

Minimum Cable Core Cross Section [mm²] ▼

Maximum Cable Core Cross Section [mm²] ▼


Minimum Cable Diameter [mm] ▼

Maximum Cable Diameter [mm] ▼

[Clear](#)
[Search →](#)

Female Metri-Pack 480 Tin Plated Terminal,
Cable Range 1.00 - 0.80 mm², Cable
Insulation Range 2.70 - 1.90 mm

Part #12124057

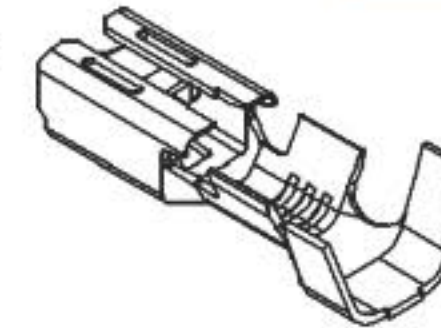

[Question about this product?](#)

[Attributes](#)
[Documents \(6\)](#)

Part #:	12124057
Description:	Female Metri-Pack 480 Tin Plated Terminal, Cable Range 1.00 - 0.80 mm ² , Cable Insulation Range 2.70 - 1.90 mm
Product Type:	Terminal
Status:	Active
Blade size [mm]:	4.8
Terminal family:	Metri-Pack
Series:	480
Gender:	Female
Sealed:	Unsealed
Material:	Tin Brass
Plating:	Tin
Minimum Cable Core Cross Section [mm²]:	0.80
Maximum Cable Core Cross Section [mm²]:	1.00
Minimum Cable Diameter [mm]:	1.90
Maximum Cable Diameter [mm]:	2.70

Certain products listed on this website may be subject to restricted usage or distribution or may not be available. For additional information, please contact your local sales office.