


Connector Location A




Connector Location B

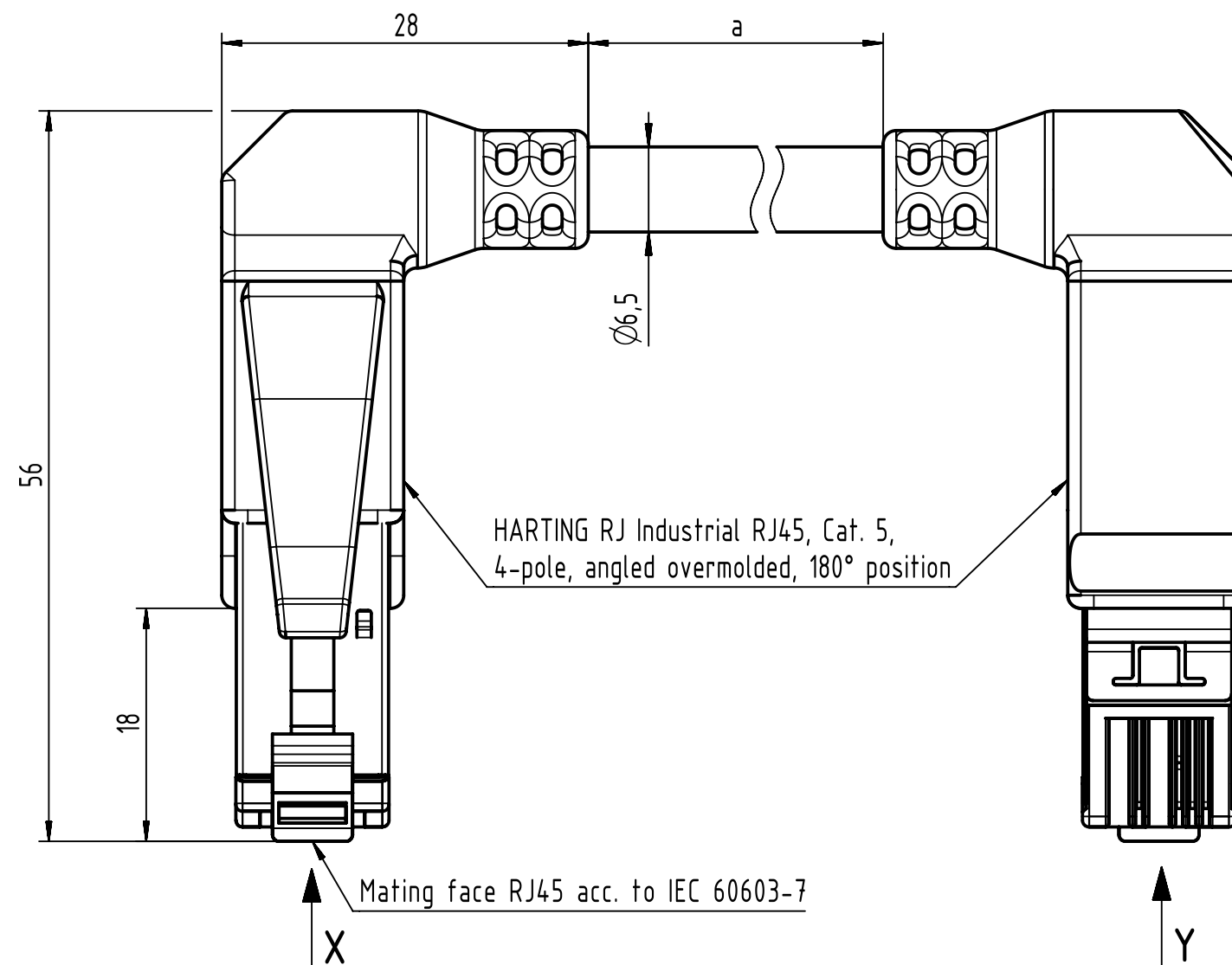

X
male

Y
male

 
Loading Plan

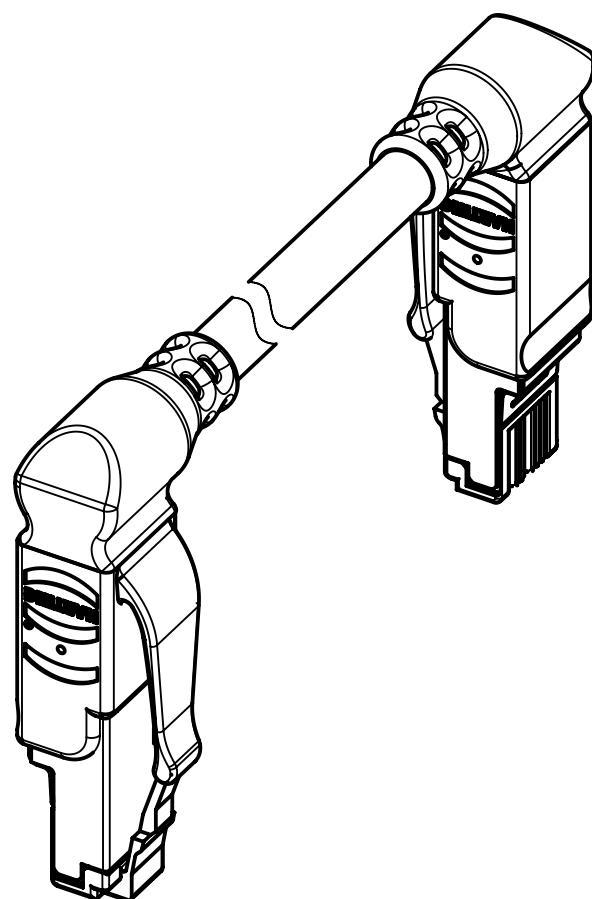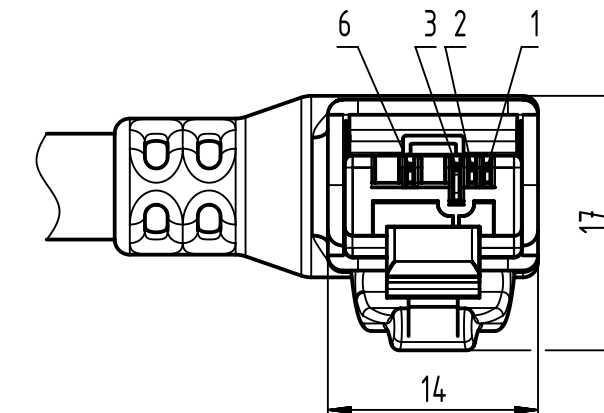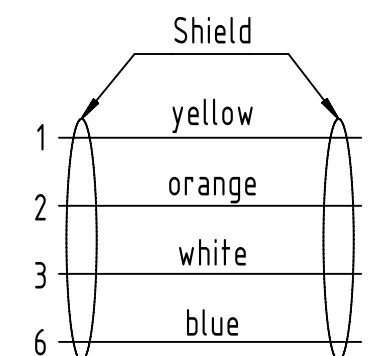

- Protection level: IP20
- Temperature range: -40°C ... +70°C

		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
All rights reserved		Created by BANCUID Banciu		Inspected by COSTEA Costea		Standardisation MUNTEANV Muntean		Date 2019-08-08	
Department HCS - RO		Title RJ Industrial Cable Assembly		Doc-Key / ECM-Nr. 100155464/UGD/004/E 500000156257		State Final Release			
HARTING Customised Solutions		Type TB		Number 094705050XX		Rev. E		Page 1/2	
D-32339 Espelkamp									

1		2		3		4		5		6		7		8										
A	53	09470505051		RJl Ethernet Trailing Cable, 4xAWG 22/7, PUR, Cat. 5+, green		5									A									
	52	09470505050				4																		
	51	09470505049				3																		
	50	09470505048				2																		
	49	09470505047				1.5																		
	48	09470505046				1																		
	47	09470505092				0.8																		
B	46	09470505045				0.5									B									
	45	09470505044				100																		
	44	09470505043				90																		
	43	09470505042				80																		
	42	09470505041				70																		
	41	09470505040				60																		
	40	09470505039				50																		
C	39	09470505038				40									C									
	38	09470505037				30																		
	37	09470505036				20																		
	36	09470505035				15																		
	35	09470505034				10																		
	34	09470505033				9																		
	33	09470505032				8																		
D	32	09470505031				7									D									
	31	09470505030				6																		
	30	09470505029				5																		
	29	09470505028				4																		
	28	09470505027				3																		
	27	09470505026				2																		
	26	09470505025				1.5																		
E	25	09470505024				1									E									
	24	09470505023				0.5																		
	23	09470505089				0.3																		
	22	09470505022				100																		
	21	09470505021				90																		
	20	09470505020				80																		
	19	09470505019				70																		
F	18	09470505018				60									F									
	17	09470505017				50																		
	16	09470505016				40																		
	15	09470505015				30																		
	14	09470505014				20																		
	13	09470505013				15																		
	12	09470505012				10																		
	11	09470505011		RJl Ethernet Standard Cable, 4xAWG 22/1, PVC, Cat. 5+, green		9																		
	10	09470505010				8																		
	9	09470505009				7																		
	8	09470505008				6																		
	7	09470505007				5																		
	6	09470505006				4																		
	5	09470505005				3																		
	4	09470505004				2																		
	3	09470505003				1.5																		
	2	09470505002				1																		
	1	09470505001				0.5																		
	Cont. no.	Part no.				Type of cable										Dim. a[m]								
	1																							
	2																							
3																								
4																								
5																								
6																								
7																								
8																								
9																								
10																								
11																								
12																								
13																								
14																								
15																								
16																								
17																								
18																								
19																								
20																								
21																								
22																								
23																								
24																								
25																								
26																								
27																								
28																								
29																								
30																								
31																								
32																								
33																								
34																								
35																								
36																								
37																								
38																								
39																								
40																								
41																								
42																								
43																								
44																								
45																								
46																								
47																								
48																								
49																								
50																								
51																								
52																								
53																								

	92	09470505088		RJl Ethernet Stranded Cable, 4xAWG 22/7, PVC outdoor, Cat. 5+, black		100							
	91	09470505087				90							
	90	09470505086				80							
	89	09470505085				70							
	88	09470505084				60							
	87	09470505083				50							
	86	09470505082				40							
	85	09470505081				30							
	84	09470505080				20							
	83	09470505079				15							
	82	09470505078				10							
	81	09470505077				9							
	80	09470505076				8							
	79	09470505075				7							
	78	09470505074				6							
	77	09470505073				5							
	76	09470505072				4							
	75	09470505071				3							
	74	09470505070				2							
	73	09470505069				1.5							
	72	09470505068				1							
	71	09470505067				0.5							
	70	09470505066				100							
	69	09470505065				90							
	68	09470505064				80							
	67	09470505063				70							
	66	09470505062				60							
	65	09470505061				50							
64	09470505060		40										
63	09470505059		30										
62	09470505091		25										
61	09470505058		20										
60	09470505057		15										
59	09470505090		12										
58	09470505056		10										
57	09470505055		9										
56	09470505054		8										
55	09470505053		7										
54	09470505052		6										
Cont. no.	Part no.		Type of cable		Dim. a[m]								
		All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing					
		All rights reserved Department HCS - RO		Created by BANCUD Banciu		Inspected by COSTEA Costea		Standardisation MUNTEANV Muntean		Date 2019-08-08		State Final Release	
HARTING Customised Solutions D-32339 Espelkamp		Title RJ Industrial Cable Assembly		Type TB		Number 094705050XX		Doc-Key / ECM-Nr. 100155464/UGD/004/E 500000156257		Rev. E		Page 2/2	