


COAXIAL CONNECTOR, BMA, 50 Ohm, Straight panel receptacle, plug (male), flange mount
13_BMA-50-0-2/199_N

Properties

- Offers a range of floating configurations
- High reliability and ease of assembly
- Intermatable with the OSP connectors series
- Applicable in frequencies up to 18 GHz

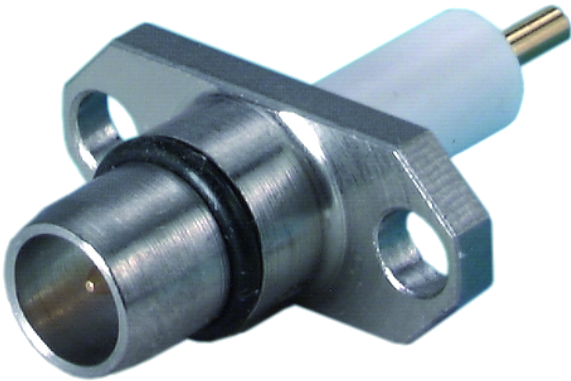

Product configuration		
Interface type	Gender	Standard
BMA	plug	IEC 60169-33_MIL-STD-348A/321

Interface and material data		
Piece parts	Material	Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer conductor	Stainless Steel	
Body	Stainless Steel	
Insulator	PFA / PTFE	
Gasket	NR (Natural Rubber)	

Electrical data	
Impedance	50 Ω
Interface frequency	18 GHz

Mechanical data	
Weight	0.0025 kg
Mating cycles	1000
Flange type	2-hole flange / 16 X 6.6
Tab style	Standard

Environmental data	
Operation temperature	-65 °C ... 125°C

COAXIAL CONNECTOR, BMA, 50 Ohm, Straight panel receptacle, plug (male), flange mount

13_BMA-50-0-2/199_N

Ordering Information Table		
Item number	Item description	Packaging type
22645623	13_BMA-50-0-2/199_NE	Single

HUBER+SUHNER is certified by ISO 9001, ISO 14001, ISO 45001, IATF 16949, AS/EN 9100 and ISO/TS 22163-IRIS. Waiver: Facts and figures herein are for information only and do not represent any warranty of any kind.
DOCUMENT PIM-P3341 / Date of publication: 26.11.2023 / uncontrolled copy