

## Housing - HC-STA-B10-HHFS-1STM32-EL-AL - 1412601

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Sleeve housing B10, for single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, lateral, height: 72 mm, cable gland: none, support sleeve: no, 1x M32, Standard

### Your advantages

- ✓ good shielding in the event of electromagnetic interference



### Key Commercial Data

Packing unit	1 pc
GTIN	 4 055626 059280
GTIN	4055626059280
Weight per Piece (excluding packing)	180.000 g
Custom tariff number	85389099
Country of origin	Poland

### Technical data

#### Dimensions

Height	72 mm
Width	44 mm
Length	73 mm

#### Ambient conditions

Degree of protection (IP)	IP66
	IP67
Degree of protection (NEMA)	4 (UL 50e)
	4X (UL 50e)

# Housing - HC-STA-B10-HHFS-1STM32-EL-AL - 1412601

## Technical data

### Ambient conditions

	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

### General


Note	For contact inserts HC-B10, BB18, DD42, M, K8/24
Size	B10
Housing type	Sleeve housing
Color	gray aluminum
Locking type	for single locking latch
No. of cable outlets	1
Cable outlet	lateral
Screw connection	none
Type of the screw connection	1x M32
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	uncoated

### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

## Drawings

Dimensional drawing

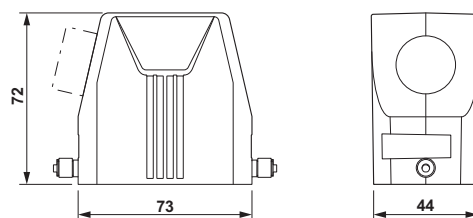

Dimensional drawing

## Classifications

eCl@ss

eCl@ss 10.0.1	27440202
eCl@ss 11.0	27440202
eCl@ss 5.1	27261200

## Housing - HC-STA-B10-HHFS-1STM32-EL-AL - 1412601

### Classifications

#### eCl@ss

eCl@ss 6.0	27261200
eCl@ss 7.0	27440202
eCl@ss 9.0	27440202

#### ETIM

ETIM 6.0	EC000437
ETIM 7.0	EC000437

#### UNSPSC

UNSPSC 13.2	31261501
UNSPSC 18.0	31261501
UNSPSC 19.0	31261501
UNSPSC 20.0	31261501
UNSPSC 21.0	31261501

### Approvals

#### Approvals

#### Approvals


UL Recognized / cUL Recognized / EAC / DNV GL / EAC / cULus Recognized

#### Ex Approvals

#### Approval details

UL Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	E255026
---------------	---	---	---------

cUL Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	E255026
----------------	---	---	---------

EAC		RU C- DE.AI30.B.01102
-----	---	--------------------------

## Housing - HC-STA-B10-HHFS-1STM32-EL-AL - 1412601

### Approvals

DNV GL



<https://approvalfinder.dnvgl.com/>

TAE000037S

EAC



RU C-  
DE.BL08.B.00511

cULus Recognized



### Accessories

#### Accessories

##### Corrugated pipe screw connection

Screw connection - WP-G HF IP66 M32 BK - 3240900



Cable gland, metric thread, IP66 protection, straight

Screw connection - WP-G HF IP69K M32 BK - 3240886



Cable gland, metric thread, IP68/69k protection, straight

Screw connection - WP-GA HF IP66 M32 BK - 3240928



Cable gland, metric thread, IP66 protection, angled

## Housing - HC-STA-B10-HHFS-1STM32-EL-AL - 1412601

### Accessories

Screw connection - WP-GA HF IP69K M32 BK - 3240914



Cable gland, metric thread, IP68/69k protection, angled

---

Screw connection - WP-GR HF IP66 M32 BK - 3240956



Cable gland, metric thread, IP66 protection, with strain relief

---

Screw connection - WP-GR HF IP69K M32 BK - 3240942



Cable gland, metric thread, IP68/69k protection, with strain relief

---

Screw connection - WP-G PP HF M32 - 3241000



Cable gland made from PP with metric thread, IP65 protection

---

Screw connection - WP-GT PP HF M32 - 3241014



Cable gland made from PP with metric thread, rotatable, IP54 protection

---

## Housing - HC-STA-B10-HHFS-1STM32-EL-AL - 1412601

### Accessories

Screw connection - WP-G BRASS IP40 M32 - 3241049



Cable gland made from brass with metric thread, IP40 protection

---

Screw connection - WP-GT BRASS M32 - 3241035



Cable gland made from brass with metric thread, rotatable, IP40 protection

---

Screw connection - WP-G BRASS IP65 M32 - 3241063



Cable gland made from brass with metric thread, IP65 protection

---

### Full screw connection

Cable gland - G-INS-M32-M68N-NNES-S - 1411166



Cable gland, cable gland material: Nickel-plated brass, external cable diameter 15 mm ... 21 mm, shielding: no, connecting thread: M32 x 1.5, color: silver, with O-ring

---

Cable gland - G-INSEC-M32-M68N-NCRS-S - 1411191



Cable gland, cable gland material: Nickel-plated brass, external cable diameter 14 mm ... 21 mm, shielding: yes, connecting thread: M32 x 1.5, color: silver, with O-ring

---

## Housing - HC-STA-B10-HHFS-1STM32-EL-AL - 1412601

### Accessories

Labeled device marker

Plastic label - US-EMLP (20X9) CUS - 0830085



Plastic label, can be ordered: by card, white, labeled according to customer specifications, mounting type: adhesive, lettering field size: 20 x 9 mm, Number of individual labels: 75

---

### Protective cover

Protective covers - HC-B10-HCLWS-PLR-BK - 1414635



Protective cover B10, with single locking latch, protective cover material: PA, height: 21.6 mm, seal: yes, diameter of retaining cord eyelet: 30 mm