

## Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2025 (250) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

### Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

## Compatible Parts



TE Part # 2151597-1  
OCEAN\_2.0\_Applicator-S-055F066O-RSM



TE Part # 1326017-9  
0.64MM AIRBAG HEADER ASSEMBLY



TE Part # 1438426-1  
0.64MM, 2POSN SEALED PLUG, BLA



TE Part # 1326042-1  
LAC CARRIER, 26 POS, 0.64MM, A KEY



TE Part # 2-638849-1  
PLUG ASSEMBLY, BLOCKED 24 POSN



TE Part # 1438454-1  
0.64MM,3 POSN SEALED PLUG ASSY



TE Part # 2151597-2  
OCEAN\_2.0\_Applicator-S-055F066O-RSA



TE Part # 1326141-1  
32WAY LAC RECEPTACLE CARRIER H



TE Part # 1326018-2  
.64MM,32P UNSEALED PLUG ASSY,B



TE Part # 1326042-2  
LAC CARRIER, 26 POS, 0.64MM, B KEY



TE Part # 638394-1  
ASSY,12P PLUG "A" KEY, W/O CPA




TE Part # 2305570-1  
Strip Terminal Cutter-Side Feed-No Crimp



TE Part # 638393-5  
10P PLUG ASSY A KEY -W/ CPA



TE Part # 2-1488107-1  
OPTION PLUG W/ CPA AND ONLY CI

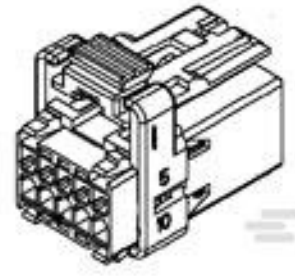

TE Part # 638397-1  
ASSY, 18P PLUG "A" KEY W/O CPA



TE Part # 7-2151597-7  
OCEAN\_2.0\_SPARE\_PART\_KIT-055F066O



TE Part # 1326133-1  
RECEPTACLE HOUSING, 18 POSITIO



TE Part # 1326018-1  
.64MM,32P UNSEALED PLUG ASSY,A



TE Part # 638394-4  
ASSY,12P PLUG "D" KEY, W/O CPA



TE Part # 1438426-3  
0.64MM, 2POSN SEALED PLUG, GRA

## Customers Also Bought



TE Part #8-1564284-1  
96POS,MCON-1.2 CB,REC HSG,ASSY



TE Part #2005388-6  
JPT SLD 2P PLUG ASSY-1S BLK



TE Part #1-2109570-2  
MCON 5P PLUG COVER TYPE-B BLK



TE Part #1-1718625-1  
3 POS HSG AMP MCP 2.8 ASSY



TE Part #1924792-6  
PLUG KIT, UNASSEM, 1 POS, RG-316  
OR RG-1



TE Part #5-1924855-4  
JACK HOUSING, 2 POSN, FAKRA, Key  
D,CpSlT



TE Part #2141494-6  
1POS,CONTACT KIT,REC HSG,ASSY,  
CODF



TE Part #550105P066  
SCL-3/4-A1-0-50MM



TE Part #505325P092  
RNF-100-3/4-A1-RD-55MM

## Documents

### Product Drawings

[0.64MM FEMALE CONTACT,AU,22AWG](#)

English

### CAD Files

Customer View Model

[ENG\\_CVM\\_1326028-4\\_C.3d\\_igs.zip](#)

English

Customer View Model

[ENG\\_CVM\\_1326028-4\\_C.3d\\_stp.zip](#)

English

Customer View Model

[ENG\\_CVM\\_1326028-4\\_C.2d\\_dxf.zip](#)

English

[3D PDF](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

## Product Specifications



## Application Specification

English

---

## Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English

[Instruction Sheet \(U.S.\)](#)

English

[Instruction Sheet \(U.S.\)](#)

English