


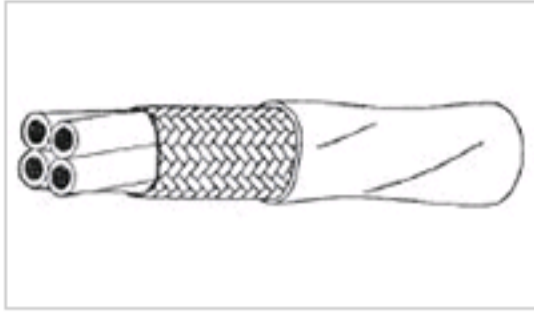

# 55PC2144-24-9/93/95/96-96 Product Details

[Share](#) | [Print](#) | [Email](#)


✔ Active

## Spec 44, Spec 55 and Spec RCW Wire and Cable

55PC2144-24-9/93/95/96-96

**55PC2144-24-9/93/95/96-96** ✔

TE Internal Number: CN7896-000

### Product Highlights [View All](#)

- Cable Type = Spec 55
- Wire Source = United States
- Cable Style = Flat Braid Shielded and Jacketed
- Wire Size (AWG/CM) = 24 AWG
- Voltage Rating = 600 VAC

- [Pricing & Availability](#) >
- [Request Sample](#) >
- [Add to My Part List](#) +
- [Buy Product through Distributor](#) >

[Feedback](#)

[Documents](#) | [Features](#) | [Compliance](#)

#### Please Note:

Use the Product Drawing for all design activity

Product Type Features		Industry Standards	
Cable Type <sup>?</sup>	Spec 55	Government/Industry Qualification	No
Cable Style	Flat Braid Shielded and Jacketed	RoHS/ELV Compliance <sup>?</sup>	RoHS compliant, ELV compliant
Electrical Characteristics		Lead Free Solder Processes <sup>?</sup>	Not relevant for lead free process
Voltage Rating (VAC)	600	RoHS/ELV Compliance History	Always was RoHS compliant
Body Features		Conditions for Usage	
Wire Size (AWG/CM)	24 AWG	Temperature Range (°C)	-65 - +200
Cable Jacket Color	White w/ Blue Stripe	Operation/Application	
Conductor Type	Silver-Coated High Strength Copper Alloy	Application	Light Weight
Wire Color	White, White w/ Orange Stripe, White w/ Green Stripe, White w/ Blue Stripe	Packaging Features	
Nominal Outside Diameter (mm [in])	2.92 [0.1149]	Wire Source	United States
Wire Diameter (mm [in])	0.90 [0.0355]	Other	
Shield Size	38 AWG	Brand	Raychem
Shield Material	Tin Plated Copper		
Configuration Features			
Number of Conductors	4		

**Related Products**

Not quite the product you're looking for?  
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Downloaded from [Arrow.com](#)