



Common Mode Choke

TCK-122


Order Code	TCK-122
Inductance (each winding)	5 μ H $\pm$ 40% (at 10 kHz / 50 mV)
Impedance (DCR)	120 m Ω max.
Rated Current	1.5 A max.
Rated Voltage	125 VDC max. (between windings)
Operating Temperature	-40°C to +105°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-122

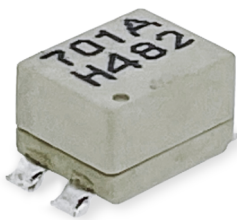

Impedance Curve

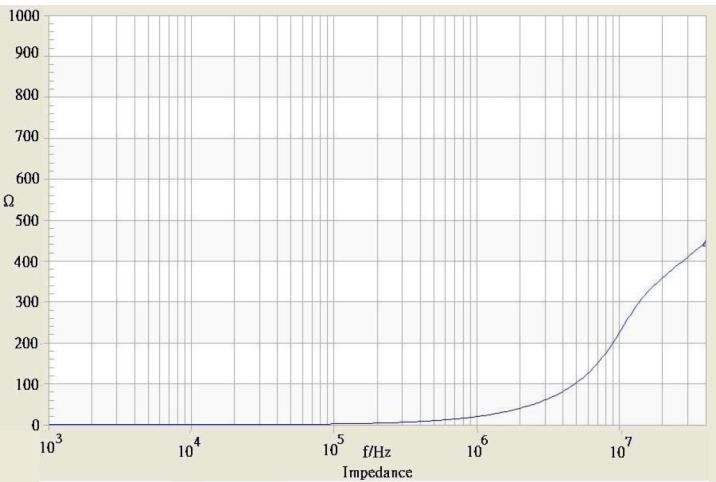

Outline Dimensions

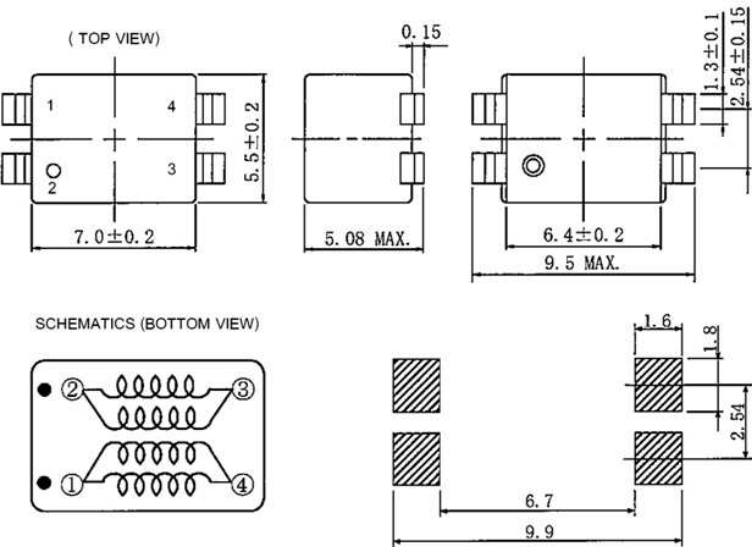

All specifications valid at +25°C, unless otherwise stated.