

5

4

3

2

1

D

D

C


C

B

B

A

A

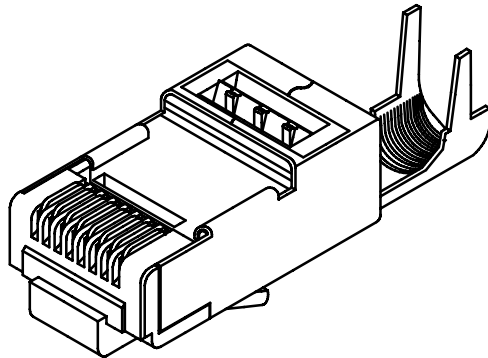

Description: Eight Conductor MOD Plug, Shield

Part No: 32-2298UL

Plug Tolerance and DIM: Complies with F.C.C requirements

Flame and Extinguish: 94-V0

Operation Temperature: -40°C to +85°C

Contact Resistance: 10 Milliohms Max.

Current/Voltage: 30 VAC/42 VDC at 1.5 AMPS

Material:


Shield .012THK CDA-260 1/4 HARD BRASS  
100-150 MICRO-INCH TIN PLATED

Housing Polycarbonate

Contact Phosphor bronze-.012THK  
Gold plated

RoHS Compliance: Yes

Technical Detail: Meets or exceeds Category 5e TIA/EIA 568-B.2

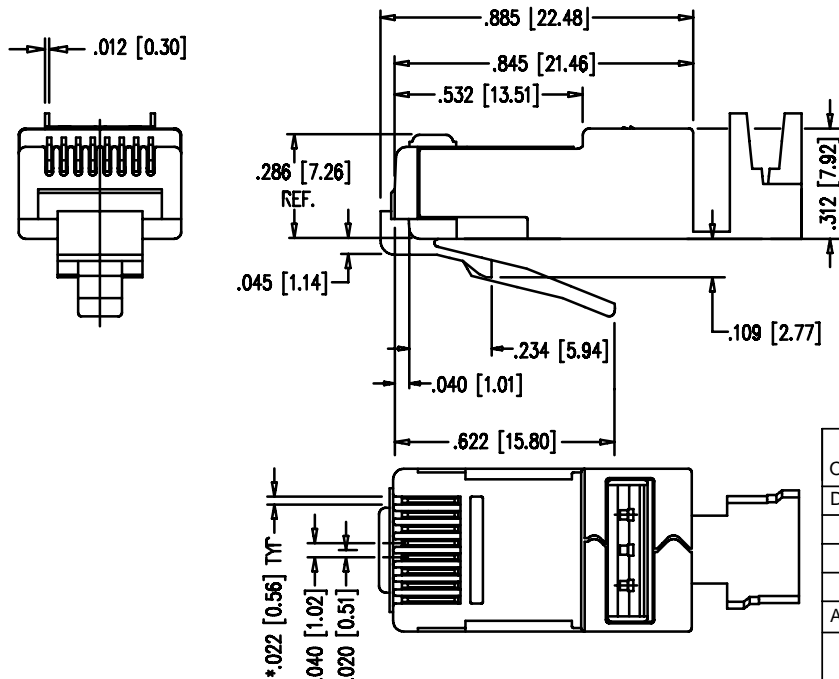

TOLERANCE UNLESS OTHERWISE SPECIFIED		DRAWN BY	DATE
DECIMALS	mm	TERRY.W	03-13-09
X	± 0.5	CHECKED BY	DATE
X.X	± 0.2	BETTY.YU	03-13-09
X.XX	± 0.1	APPROVED BY	DATE
ANGLES	± 0.5°	THOMAS	03-16-09
		U/M	mm

THIS DRAWING WAS PRODUCED BY COMPUTER,  
DO NOT SCALE DRAWING OR UPDATE MANUALLY.

DRAWING NO.

32-2298UL-CUST

REVISIONS

01

OFFICIAL RELEASE

10-13-09

T

W

B

Y

T

02

TYPO MISTAKE: BRESS SHOULD  
BE BRASS  
UPDATE SPECIFICATIONS

08-14-12

Y

G

Y

G

M

L

ECO-12-0208

CUSTOMER COPY



Connectivity  
Solutions

TITLE

Eight Conductor MOD Plug, Shield

SHEET  
1 OF 1

DRAWING NO.

32-2298UL-CUST

SIZE

A

5

4

3

2

1