



LABEL AND LINER DESIGN

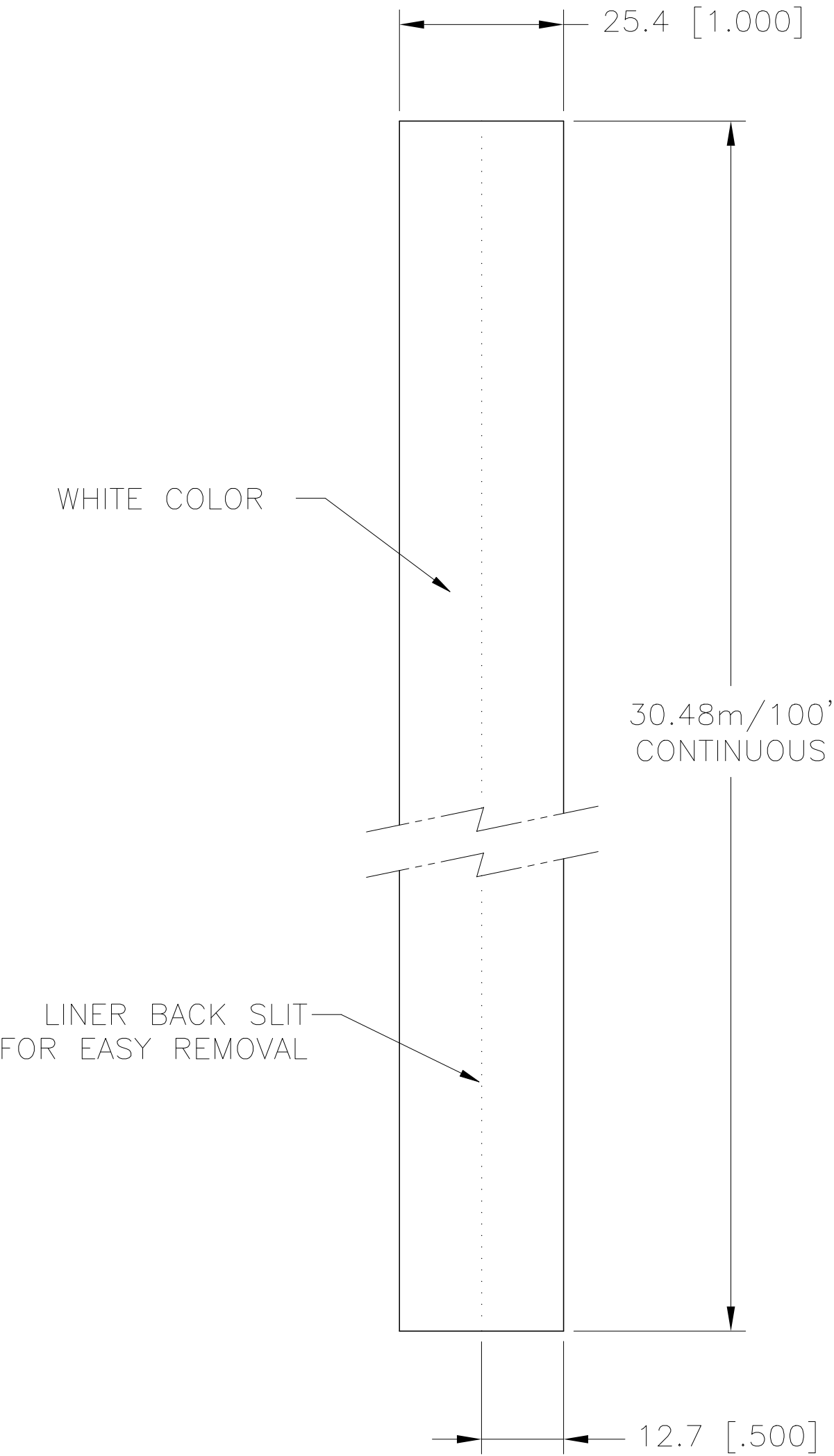

PRESENTATION

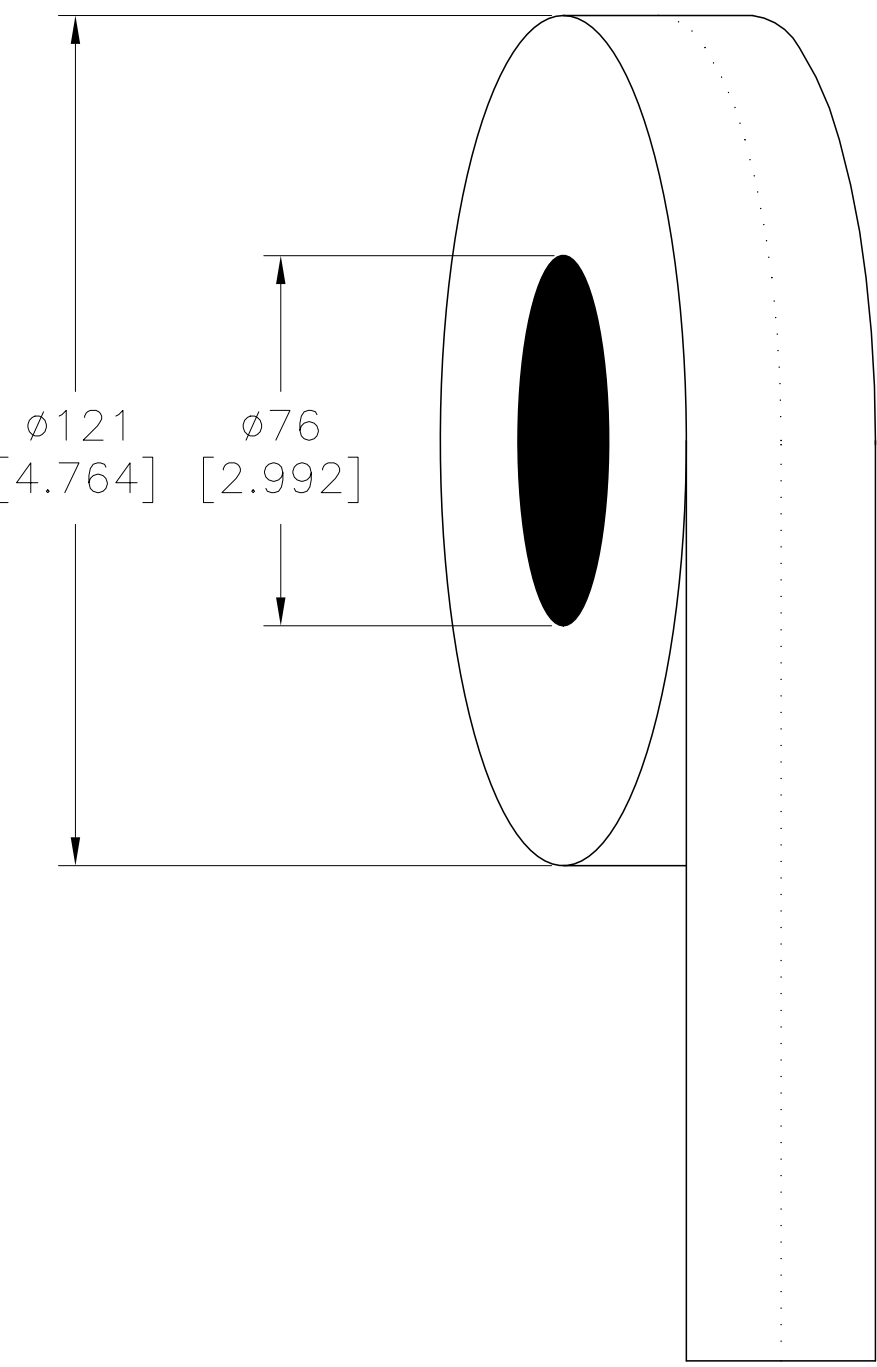

All dimensions in mm [Inch]

TE PN: 160892-000

OUTSIDE WOUND (BACK SLIT CENTRED)
LABEL ACROSS: 1
PER ROLL QTY: 30.48m / 100 feet

TOLERANCES mm [INCH]		THIS DRAWING IS A CONTROLLED DOCUMENT.		DWN 12MAY2020 GOPALKRISHNA HV		 TE Connectivity									
LABEL HEIGHT:	±0.3 [.012]	DIMENSIONS: mm [INCHES] 		CHK 12MAY2020 D.BURGAT											
LABEL WIDTH:	±0.3 [.012]			APVD 12MAY2020 D.BURGAT		NAME TEDLAR® LABEL – WHITE – CONTINUOUS 25.4mm x 30.4m (1inch x 100ft) —									
WEB WIDTH:	±0.8 [.031]			PRODUCT SPEC TTDS-005											
VERTICAL REPEAT:	±0.8 [.031]*			APPLICATION SPEC —											
HORIZONTAL REPEAT:	±0.8 [.031]*			TOLERANCES UNLESS OTHERWISE SPECIFIED: 0 PLC ± ± 1 PLC ± - 2 PLC ± - 3 PLC ± - 4 PLC ± - ANGLES ± -		SIZE		CAGE CODE	DRAWING NO	RESTRICTED TO					
PRINT POSITIONING:	±0.8 [.031]*	WEIGHT 106g				A2	FB1U7	C- TTVF100WE-100							
LEFT MARGIN:	±0.4 [.016]	MATERIAL				FINISH		GLOSS		—					
QUANTITY:	-0 % +2 %	SEE TABLE				CUSTOMER DRAWING				SCALE	NTS	SHEET	1 of 1	REV	A
*NON ACCUMULATING															

MATERIAL	POLYVINYL FLUORIDE (TEDLAR®)
ADHESIVE TYPE	PERMANENT ACRYLIC
LINER	BROWN KRAFT

D.BURGAT		TE Connectivity	
D.BURGAT		NAME	
PRODUCT SPEC		TEDLAR® LABEL – WHITE – CONTINUOUS	
APPLICATION SPEC		25.4mm x 30.4m (1inch x 100ft)	
—		—	
106g		A2 FB1U7	
CUSTOMER DRAWING		C=TTVF100WE-100	
		RESTRICTED TO	
		—	
		SCALE NTS	
		SHEET 1 OF 1	
		REV A	