


# Terminal Blocks - Single Row

## All Series Marking Options Single Row Terminal Blocks

### Marking Options & Accessories

#### Standard Marking


Markings are applied directly to the sides of Series 1000, 2000, 3000, and 4000. Standard characters are white and 1/8" high. Factory may substitute 3/32" high characters.

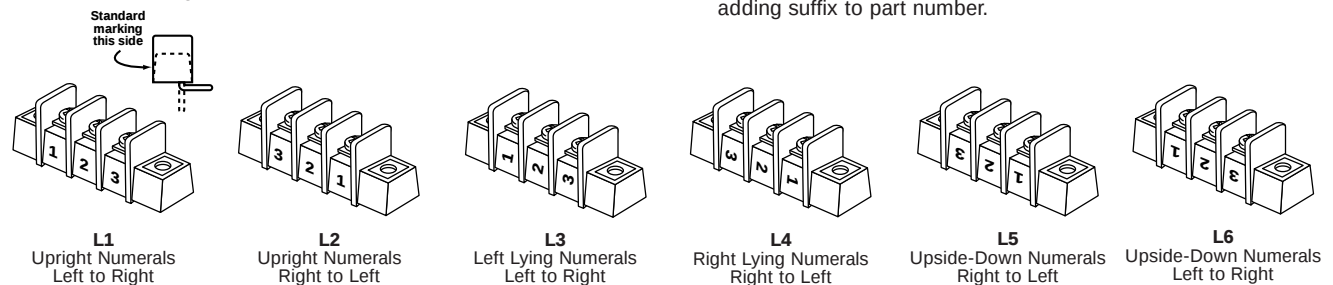

Blocks to be marked on both sides require a different code for each side. Example: "L1" on one side of the block requires "L2" on the other side to ensure common terminal marking. Specify by adding suffix to part number.

#### Special Marking


Special markings are available for Series 1000, 2000, 3000, 4000 & 5000 at an additional charge for preparation. Production charges for setup, handling and marking are the same as for standard marking and the same quantity discounts apply. Consult factory for price and delivery.

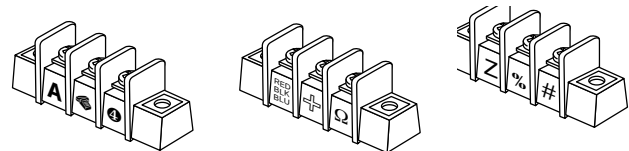

#### Closed Barrier Terminal Block Marking Options


L1 & LT1 = Upright numerals, numbered from left to right  
L2 & LT2 = Upright numerals, numbered from right to left  
L3 = Left lying numerals, numbered from left to right  
L4 = Right lying numerals, numbered from right to left  
L5 & LT5 = Upside down numerals, numbered from right to left  
L6 & LT6 = Upside down numerals, numbered from left to right

**Options LT1 - LT6  
Top Marking**  
For high visibility in tight packages.

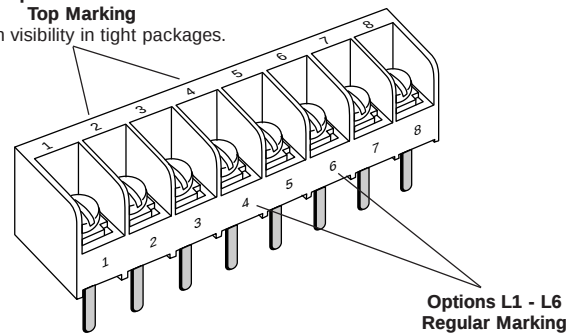

#### Marker Strips

 Black marker strips with white numerals mount beneath the terminal blocks to clearly identify terminal and wire positions. Available with forward or reverse markings, top or bottom of strip. If special markings are required, submit a drawing.



Bottom Forward - BF

Top Forward - TF

Bottom Reverse - BR

Top Reverse - TR

#### Series



**MS1** - 1000 Series  
**MS2** - 2000 Series  
**MS3** - 3000 Series

#### Base



**1** - mount end, feed thru  
**2** - barrier end, feed thru  
**3** - mount end, insulator tubes  
**4** - barrier end, insulator tubes  
**5** - mount end, non feed-thru

#### Poles



**02 to 36**

#### Marking



**BF** - bottom forward  
**TF** - top forward  
**BR** - bottom reverse  
**TR** - top reverse

## All Series Accessories

### Single Row Terminal Blocks *Continued*

#### Cover Options - Single Row

##### Terminal Block Covers

Available for Series A1000, A2000, A3000, A4000, CB2000, CB3000, LP2000, & LP3000.

Three styles of UL 94V0 thermoplastic covers are offered in black. Covers are ordered separately and supplied with two clips each, unless ordered without clips. Optional markings may be specified (black on yellow; white on black).

 
Notes: Covers can not be used with:

- mounting plate options MP & MT.
- certain quick connect terminals.
- 0, 6, & 9 base/end styles on A2 or A3

Bulk Cover Clips: Series 1000 = **CC1-J**; Series 2000 & 3000 = **CC2-J**; Series 4000 = **CC4-J**.

##### Standard Cover Markings


Top Forward - **TF**



Bottom Forward - **BF**

Skirted Access Side

 Top Reverse - **TR**




Bottom Reverse - **BR**


Skirted Access Side



**Cover Options  
BB & CB**  
Skirted access  
on both sides.

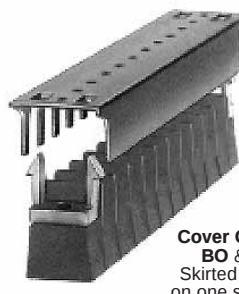

**Cover Options  
BO & CO**  
Skirted access  
on one side only.

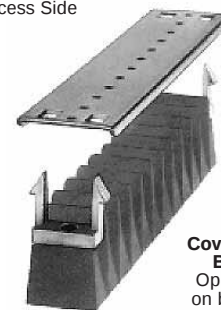

**Cover Options  
BC & TC**  
Open access  
on both sides.

##### Cover



**BB** - skirted access, both sides, black  
**BO** - skirted access, one side, black  
**BC** - open access, both sides, black\*

\* Not available in 4000 Series

##### Series



**1** - 1000  
**2** - 2000  
**3** - 3000  
**4** - 4000

##### Poles



**02 to 36**

##### Markings



**BF** - bottom forward  
**TF** - top forward  
**BR** - bottom reverse  
**TR** - top reverse

##### Options



**00** - without clips

#### Snap-On Covers for A38/B38/F38 Series & CB2/CB3 Series

##### A38/B38 Series



| Poles      |                            |
|------------|----------------------------|
| <b>TA8</b> | - <input type="checkbox"/> |
| <b>TB8</b> | - <input type="checkbox"/> |
| <b>FB8</b> | - <input type="checkbox"/> |

**A38 Series**

**B38 Series**

**F38 Series**

##### CB2/CB3 Series



| Poles      |                            |
|------------|----------------------------|
| <b>T02</b> | - <input type="checkbox"/> |
| <b>T03</b> | - <input type="checkbox"/> |

**CB2 Series**

**CB3 Series**