

DSUB LOOSE PART CRIMP CONTACT

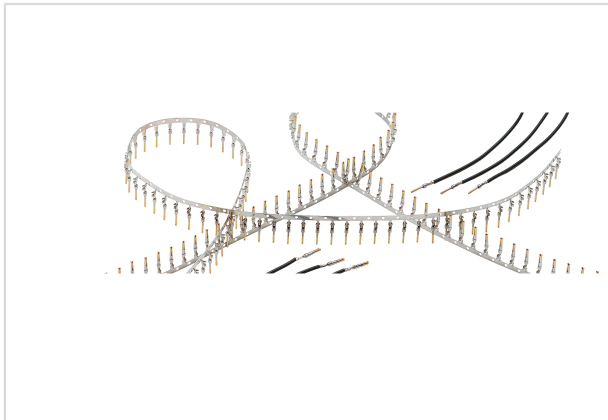


Image is for illustration purposes only. Please refer to product description.

Part number	09 67 000 8178
Specification	DSUB LOOSE PART CRIMP CONTACT
HARTING eCatalogue	https://b2b.harting.com/09670008178

Identification

Category	Contacts
Series	D-Sub
Identification	Standard
Type of contact	Crimp contact

Version

Gender	Male
Manufacturing process	Stamped contacts

Technical characteristics

Conductor cross-section	0.25 ... 0.52 mm ²
Conductor cross-section	AWG 24 ... AWG 20
Contact resistance	≤10 mΩ
Performance level	2

Material properties

Material (contacts)	Copper alloy
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No



Pushing Performance

Material properties

ECHA SCIP number ecef7555-f643-4ceb-a337-fc54762297f1

Commercial data

Packaging size	500
Net weight	0.13 g
Country of origin	Germany
European customs tariff number	85366990
eCl@ss	27440204 Contact for industrial connectors