
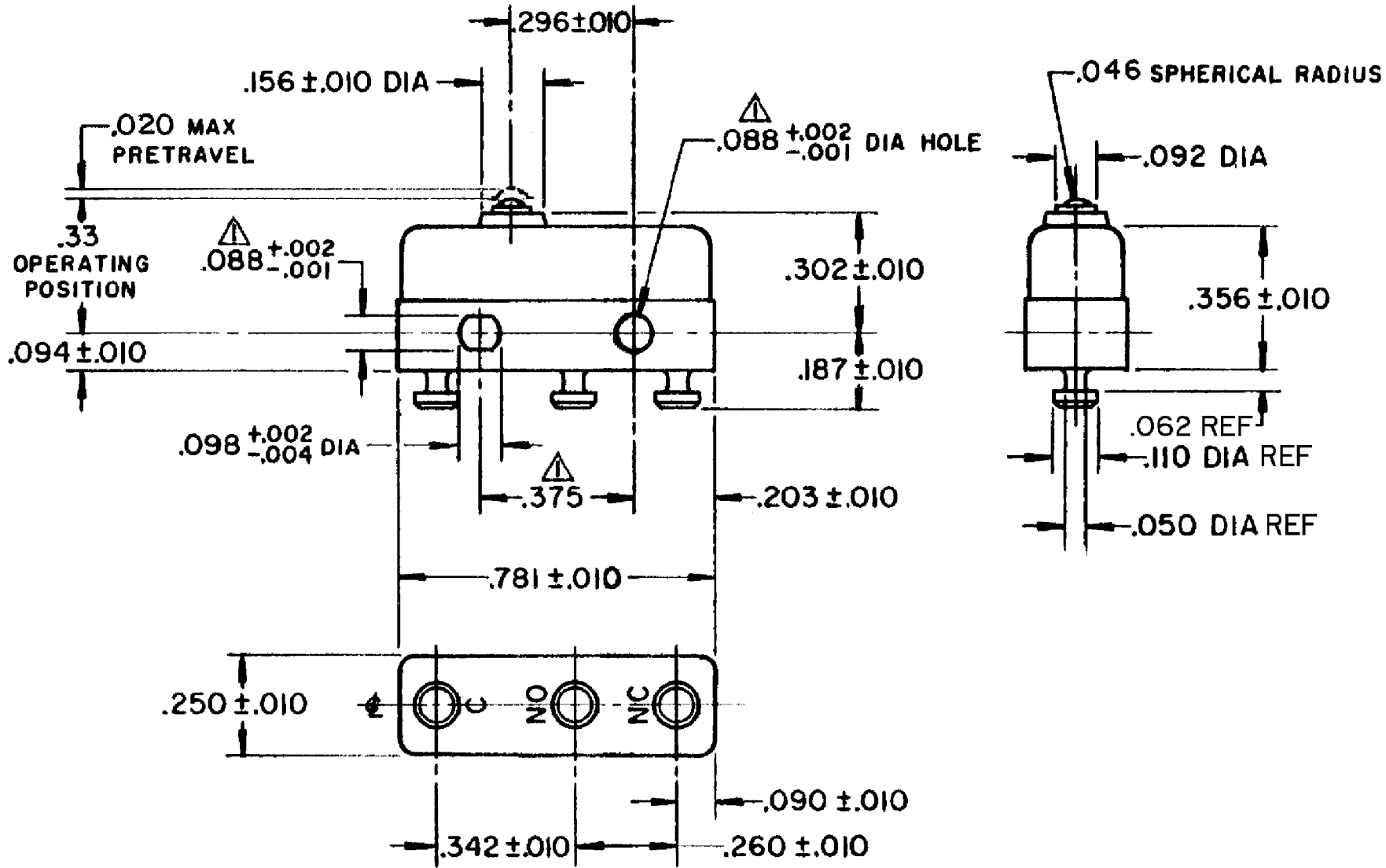


HONEYWELL PART NUMBER
22SM157-T
PRODUCT CODE TXQ5760
JG-80725

REV	DOCUMENT	CHANGED BY	CHECK
7	0038444	KVS 09APR08	ASD

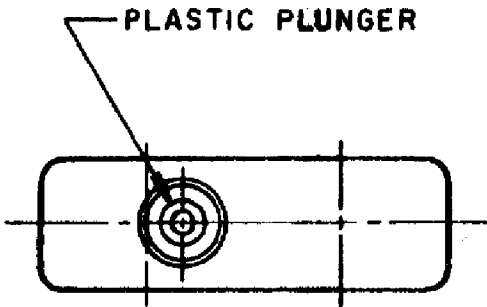

- NOTES
- ▲-MOUNTING HOLES WILL ACCEPT PINS OR SCREWS OF .087 MAX DIA ON .375 ± .002 CENTERS
 - 2-TERMINALS ARE PLATED FOR SOLDERING
 - 3- SWITCH WILL WITHSTAND TEMPERATURE OF 250° F

RELEASE NO.
SR-9084
REPLACES
-

CHARACTERISTICS		ELECTRICAL DATA		DESIGN UNITS: INCH TOLERANCES UNLESS NOTED: NO PLACE X ± ONE PLACE .X ± TWO PLACE .XX ± THREE PLACE .XXX ± FOUR PLACE .XXXX ± ANGLES ± THIRD ANGLE PROJECTION 		DRAWN	VK	20 FEB 08	Honeywell				
OPERATING FORCE — — — — 3-7 OZ		CONTACT ARRANGEMENT SPDT				CHECK	RJ	20 FEB 08					
RELEASE FORCE— — — — 1 OZ MIN		30 VOLTS DC RATING		0.030 0.015 0.005		THIS DRAWING COVERS A PROPRIETARY ITEM AND IS THE PROPERTY OF HONEYWELL. THIS DRAWING IS NOT TO BE COPIED OR USED WITHOUT THE PERMISSION OF HONEYWELL.			TITLE SWITCH - BASIC				
DIFFERENTIAL TRAVEL— — — .004 MAX			SEA LEVEL										
OVERTRAVEL — — — — — .003 MIN		INDUCTIVE 5 AMP				INTERPRET PER ANSI Y14.5M-1982 OTHER HONEYWELL ENGINEERING STANDARDS MAY APPLY			SIZE	TYPE	DRAWING NAME		REV
		RESISTIVE 10AMP							B	I	22SM157-T		7
						RASTER			SCALE	-	WEIGHT .006 LB MAX	SHEET 1 OF 1	

