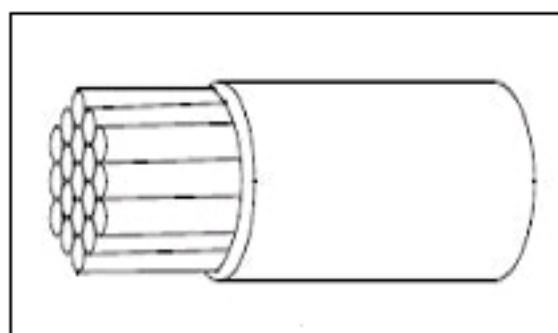


22759/32-30-5 Product Details

[!\[\]\(e3f8612927870f2e0f9f5989e6dd3064_img.jpg\) Share](#) [!\[\]\(a86c7d1c9cb81c81614634a31267440d_img.jpg\) Print](#) [!\[\]\(ce158fc5e55633398941d0898ae45661_img.jpg\) Email](#)

22759/32-30-5

TE Internal Number: 632749-000

 Obsolete[Contact Product Information Center](#)

Spec 44, Spec 55 and Spec RCW Wire and Cable

[Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Cable Type = Spec 55
- Wire Source = United States
- Cable Style = Primary
- Wire Size (AWG/CM) = 30 AWG
- Voltage Rating = 600 VAC

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#)[Request Sample](#)[Find Similar Products](#)[Buy Product](#)

Documentation & Additional Information

Product Drawings:

- None Available

Related Products:

- [Tooling](#)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Cable Type](#) = Spec 55
- [Cable Style](#) = Primary
- Number of Conductors = 1

Conditions for Usage:

- Temperature Range (°C) = -65 – +150
- Wire Size - Details = 30 AWG 0.057 mm², 0.00009 in², 7 x 38 AWG

Electrical Characteristics:

- Voltage Rating (VAC) = 600

Operation/Application:

- Application = General Purpose - Lightweight

Body Features:

- Wire Size (AWG/CM) = 30 AWG
- Conductor Type = Tin-Plated Copper
- Wire Color = Green
- Nominal Outside Diameter (mm [in]) = 0.61 [0.024]
- Wire Diameter (mm [in]) = 0.61 [0.024]
- Conductor O.D. (mm [in]) = 0.31 [0.012]

Packaging Features:

- Wire Source = United States

Industry Standards:

- Government/Industry Qualification = Yes
- Government/Industry Part Number = M22759/32-30-5
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- Brand = Raychem

Corporate Information

[Who We Are](#)[Investors](#)[News Room](#)[Supplier Portal](#)[Careers](#)

Quick Links

[Check Distributor Inventory](#)[Cross Reference](#)[Find Documents & Drawings](#)[Product Compliance Support Center](#)[Site Map](#)

Customer Support

[Email or Chat With Us](#)[Find a Phone Number](#)[Search Knowledge Base](#)[Manage your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address 