


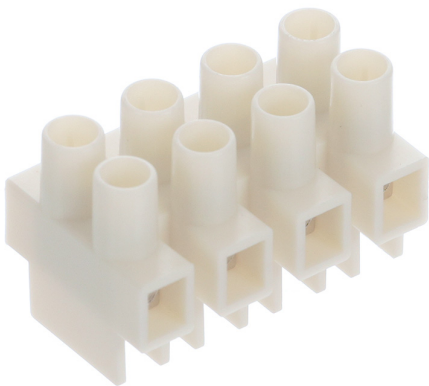

Part Number : [391001804](#)
Product Description : 8.00mm Pitch Beau
Eurostyle Two-Screw Terminal Strips, 4
Circuits
Series Number : 39100
Status : Active
Product Category : Terminal Blocks and
Barrier Strip
Engineering Number : M800-01-04-5-M1




Documents & Resources

Drawings
[391001804_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Contains Lead per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

Part Details

General

Status	Active
Category	Terminal Blocks and Barrier Strip
Series	39100
Description	8.00mm Pitch Beau Eurostyle Two-Screw Terminal Strips, 4 Circuits
Application	Wire-to-Wire
Component Type	One Piece
Product Name	Eurostyle Two Screw
Type	Terminal Strips
UPC	78172545122

Electrical

Current - Maximum per Contact	20.0A
Voltage - Maximum	600V

Physical

Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	White
Entry Angle	Horizontal
Lock to Mating Part	None
Material - Metal	Stainless Steel
Material - Resin	Nylon
Net Weight	10.750/g
Number of Rows	2
Orientation	Vertical
Panel Mount	Mounting Holes Between Circuit
PCB Retention	Yes
Pitch - Mating Interface	8.00mm
Pitch - Termination Interface	8.00mm

Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size (AWG)	12, 14, 16, 18, 20, 22

This document was generated on Apr 26, 2025