

FPM-5151G FPM-5171G FPM-5191G

15" XGA/17" SXGA/19" SXGA Industrial Monitors with Resistive Touchscreens, Direct-VGA, and DVI Ports



Features

- 15" XGA or 17" / 19" SXGA TFT LCD LED backlight
- Direct VGA & DVI-D input interface
- Lockable OSD keys with 2 user-defined contrast/brightness settings
- Flat-sealed front panel
- Robust design with anti-rust chassis and aluminum die-cast front panel
- Front accessible USB connector
- Combo RS-232 & USB interface for touchscreen function (optional)
- Supports industrial 10-30 V_{DC} power input with Phoenix jack
- Supports panel, wall, desktop, rack or VESA arm mounting
- Front panel is IP65 compliant

Introduction

The FPM-5000G series provides 15", 17" and 19" color TFT LCD with LED backlight flat panel monitors specifically designed for industrial applications. With a viewing size from 15" to 19", they present ample display areas as well as vivid and sharp images. It features Direct-VGA & DVI-D signal transmission, which allows VGA control cards to be used in your system. The onscreen display allows users to adjust the images on the screen with two user-defined settings. The front access USB connector provides easy access the controller, and the industrial 10-30 V_{DC} wide range power support makes this product an excellent option for Factory and Machine Automation display solutions.

Specifications

General

- **Button Controls** OSD control pad on rear side with lockable function
- **Certification** BSMI, CCC, CE, FCC Class A, UL
- **Dimensions (WxHxD)**
 - 5151G: 449.92 x 315.63 x 50.5 mm (17.71" x 12.43" x 2")
 - 5171G: 481.9 x 355.9 x 55 mm (18.97" x 14.01" x 2.17")
 - 5191G: 481.93 x 384.6 x 59 mm (18.97" x 15.14" x 2.32")
- **Enclosure**
 - Front panel: Aluminum and flat-sealed
 - Rear cover: Anti-rust coating
- **Mounting** Panel, wall, desktop, VESA arm, or 19" rackmount
- **Power Input**
 - Phoenix Jack - 10 ~ 30 V_{DC} input
 - Optional external 57 W power adapter, with AC 100 V ~ 240 V input and DC +12 V @ 4.7A output
- **Power Consumption** 18 W + 20%/31 W + 20%/32 W + 20%
- **USB** Front USB access for extension
- **Video Port** VGA & DVI-D
- **Weight (Net)** 6 kg (13.22 lbs)/8 kg (17.63 lbs)/10 kg (22.04 lbs)

LCD Display

- **Display Type** XGA/SXGA/SXGA TFT LCDs
- **Display Size** 15"/17"/19"
- **Max. Resolution** 1024 x 768/1280 x 1024/1280 x 1024
- **Max. Color** 16.2M
- **Viewing Angle (H/V°)** 160/130, 170/160, 170/160
- **Luminance (cd/m²)** 400/350/350
- **Backlight Life (hrs)** 50,000
- **Contrast Ratio** 700:1 / 800:1 / 1000:1

Touchscreen (Optional)

- **Sensor** AMT
- **Driver** Penmount 6000
- **Type** 5-wire Resistive
- **Interface** RS-232 & USB
- **Lifespan** 10/10/36 million with a silicone rubber of R8 finger, writing rate is by 250g at 2 times/s
- **Light Transmission** > 80%
- **OS Support** Windows 2000, XP, Vista, 7, XPe, CE and Linux
- **Power Consumption** +5 V @ 100 mA
- **Touch Resolution** Linearity

Environment

- **Operation Temperature** 0 ~ 50°C (32 ~ 122°F)
- **Storage Temperature** -20 ~ 60°C (-4 ~ 140°F)
- **Humidity (Storage)** 10 ~ 90% non-condensing
- **Waterproof** Front panel is IP65 compliant
- **Vibration** 5 ~ 500 Hz, 1 Grms (Operating, Random)


Ordering Information

- **FPM-5191G-X0BE** 19" SXGA Ind. Monitor
- **FPM-5191G-R3BE** 19" SXGA Ind. Monitor w/Resistive TS(RS-232,USB)
- **FPM-5171G-X0BE** 17" SXGA Ind. Monitor
- **FPM-5171G-R3BE** 17" SXGA Ind. Monitor w/Resistive TS(RS-232,USB)
- **FPM-5151G-X0BE** 15" XGA Ind. Monitor
- **FPM-5151G-R3BE** 15" XGA Ind. Monitor w/Resistive TS(RS-232,USB)

FPM-5151G/FPM-5171G/FPM-5191G

Dimensions

Unit: [mm]

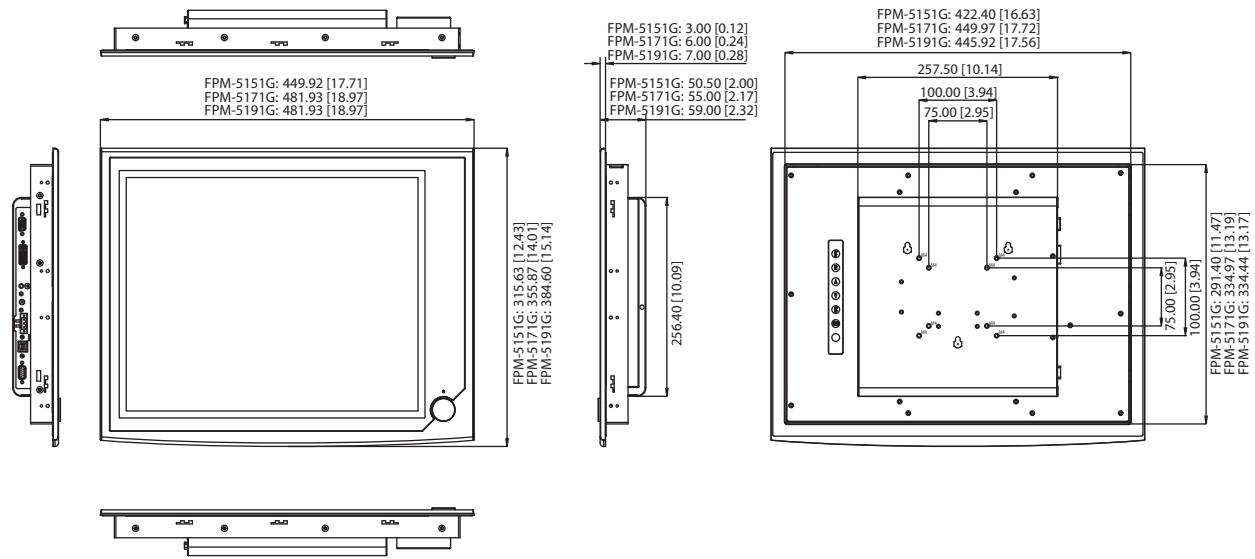


Accessories

- **FPM-5151G-SMKE** FPM-5151G/5171G Stand Kit
- **FPM-5191G-SMKE** FPM-5191G Stand Kit
- **IPPC-6152A-RMKE** IPPC-6152A/FPM-5151G Rack Mount Kit
- **IPPC-6172A-RMKE** IPPC-6172A/FPM-5171G Rack Mount Kit
- **IPPC-6192A-RMKE** IPPC-6192A/FPM-5191G Rack Mount Kit
- **1702002600** Power Cable US Plug 1.8 M
- **1702002605** Power Cable EU Plug 1.8 M
- **1702031801** Power Cable UK Plug 1.8 M
- **1702031836** Power Cable China/Australia Plug 1.8 M
- **1757003822** ADAPTER 100-240V57W12V4.75A W/O PFC SPU63-105 L5

Note: VESA mounting screw length: M4x6mm

I/O View

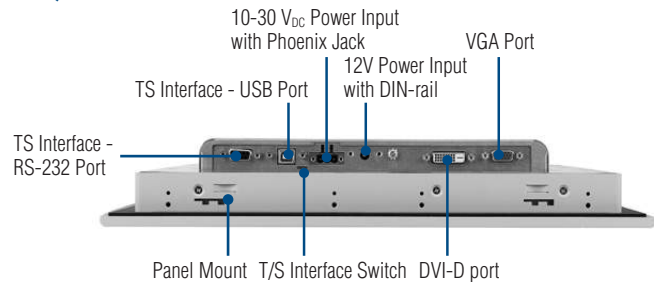

Front Accessible USB Port



Back View

