


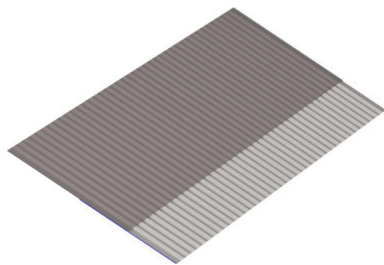

**Part Number :** [982660433](#)  
**Product Description :** 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 127.00mm Cable Length, Tin (Sn) Plating, 40 Circuits  
**Series Number :** 98266  
**Status :** Active  
**Product Category :** Flat-Flexible Cable (FFC)



## Documents & Resources

### Drawings

- [982660433 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

### Specifications

- [PS-98266-001-001.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                                                                           |
|--------------------|-----------------------------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                                              |
| China RoHS         |  per SJ/T 11365-2006 |
| EU ELV             | Not Relevant                                                                                              |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21                                                                        |
| REACH SVHC         | Not Contained per D(2025)4165-DC (25 June 2025)                                                           |
| EU RoHS            | Compliant per EU 2015/863                                                                                 |

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

---

**Part Details**

**General**

|              |                                                                                                                       |
|--------------|-----------------------------------------------------------------------------------------------------------------------|
| Status       | Active                                                                                                                |
| Category     | Flat-Flexible Cable (FFC)                                                                                             |
| Series       | 98266                                                                                                                 |
| Description  | 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 127.00mm Cable Length, Tin (Sn) Plating, 40 Circuits |
| Comments     | Contacts on the same side, Type A                                                                                     |
| Product Name | Premo-Flex FFC Jumper                                                                                                 |
| UPC          | 756054768877                                                                                                          |

**Electrical**

|                               |        |
|-------------------------------|--------|
| Current - Maximum per Contact | 0.5A   |
| Voltage - Maximum             | 60V AC |

**Physical**

|                           |                |
|---------------------------|----------------|
| Cable Length              | 127.00mm       |
| Circuits (Loaded)         | 40             |
| Contact Layout Type       | A (same side)  |
| Design Feature            | Extra-Flexible |
| Material - Plating Mating | Tin            |
| Net Weight                | 1.658/g        |
| Packaging Type            | Bag            |
| Pitch - Mating Interface  | 0.50mm         |

|                               |                 |
|-------------------------------|-----------------|
| Temperature Range - Operating | -40° to +105°C  |
| Termination Style             | FFC Connector   |
| Wire/Cable Type               | Flat Flex Cable |
| Wire Size (AWG)               | N/A             |

---

## Mates With / Use With

### Mates with Part(s)

| Description                                                                                                                          | Part Number                       |
|--------------------------------------------------------------------------------------------------------------------------------------|-----------------------------------|
| Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 40 Circuits, Copper Alloy, Tin-Bismuth Plating      | <u><a href="#">5019514000</a></u> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 40 Circuits, Tin-Bismuth Plating                    | <u><a href="#">525594072</a></u>  |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 40 Circuits, Tin-Bismuth Plating    | <u><a href="#">541044096</a></u>  |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 40 Circuits, Tin-Bismuth Plating | <u><a href="#">541324097</a></u>  |

---

This document was generated on Sep 17, 2025