




**Part Number :** [512961294](#)

**Product Description :** Easy-On FFC/FPC Connector, 0.50mm Pitch, 1.30mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 12 Circuits, Gold (Au) Contact Plating

**Series Number :** 51296

**Status :** Not Recommended For New Design

**Product Category :** FFC / FPC Connectors

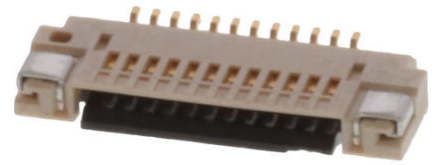

---

## Documents and Resources

### Drawings

[512961294 sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

[Symbol and Footprint \(Multi-Format\)](#)

### Specifications


[SPK-51296-007-001.pdf](#)

[PS-51296-003-001.pdf](#)

---

## Product Environment Compliance

### Compliance

|                    |   |
|--------------------|---|
| GADSL/IMDS         | Not Relevant  |
| China RoHS         |  per SJ/T 11365-2006 |
| EU ELV             | Not Relevant  |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21  |
| REACH SVHC         | Not Contained per D(2025)7771-DC (04 Feb 2026)  |
| EU RoHS            | Compliant per EU 2015/863   |

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### Substances of Interest

- PFAS

### EU RoHS Certificate of Compliance

### Additional Product Compliance Information

---

## Part Details

### General

|              |   |
|--------------|---|
| Status       | Not Recommended For New Design  |
| Category     | FFC / FPC Connectors  |
| Series       | 51296   |
| Description  | Easy-On FFC/FPC Connector, 0.50mm Pitch, 1.30mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 12 Circuits, Gold (Au) Contact Plating |
| Product Name | Easy-On   |
| UPC          | 822348727612  |

### Agency

|    |        |
|----|--------|
| UL | E29179 |
|----|--------|

### Electrical

|                               |      |
|-------------------------------|------|
| Current - Maximum per Contact | 0.5A |
| Voltage - Maximum             | 50V  |

### Physical

|               |            |
|---------------|------------|
| Actuator Type | Front Flip |
|---------------|------------|

|                                |                       |
|--------------------------------|-----------------------|
| Circuits (Loaded)              | 12                    |
| Color - Resin                  | Beige, Black          |
| Contact Position               | Bottom                |
| Durability (mating cycles max) | 20                    |
| Mated Height                   | 1.30mm                |
| Material - Metal               | Phosphor Bronze       |
| Material - Plating Mating      | Gold                  |
| Material - Plating Termination | Gold                  |
| Net Weight                     | 76.700/mg             |
| Orientation                    | Right Angle           |
| Packaging Type                 | Embossed Tape on Reel |
| PCB Locator                    | No                    |
| PCB Mounting                   | Surface Mount         |
| PCB Retention                  | No                    |
| Pitch - Mating Interface       | 0.50mm                |
| Polarized to PCB               | Yes                   |
| Stackable                      | No                    |
| Temperature Range - Operating  | -40° to +85°C         |
| Wire/Cable Type                | FFC/FPC               |

---

## Mates With / Use With

### Mates with Part(s)

| Description                         | Part Number  |
|-------------------------------------|--------------|
| 0.50mm Pitch Premo-Flex FFC Jumpers | <u>15020</u> |
| 0.50mm Pitch Premo-Flex FFC Jumpers | <u>15120</u> |

---

This document was generated on Apr 21, 2026