
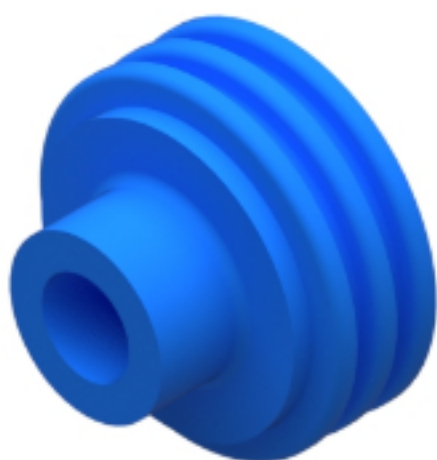



SEARCH KEYWORD, PART NUMBER 



Part Number: 15324999

SINGLE WIRE SEAL FITS TO 12.50 mm CAVITY

 [Share](#)  [Print](#) [Contact Us About This Item](#)

GET SAMPLES 

ATTRIBUTES




DOCUMENTS

ECAD

Attributes

Type	SINGLE WIRE SEAL	Hardness (Shore)	50
Outer Diameter (mm)	13.05	Contains Lubricant (Oil Content)	Low
Borehole Diameter (mm)	3.15	Restraint Ring	No
Length (mm)	8.5	Min. operating temperature	-40°C
Min Cable Outer Diameter (mm)	3.61	Max. operating temperature	+140°C
Max Cable Outer Diameter (mm)	4.5		
Color	BLUE		

Other Products

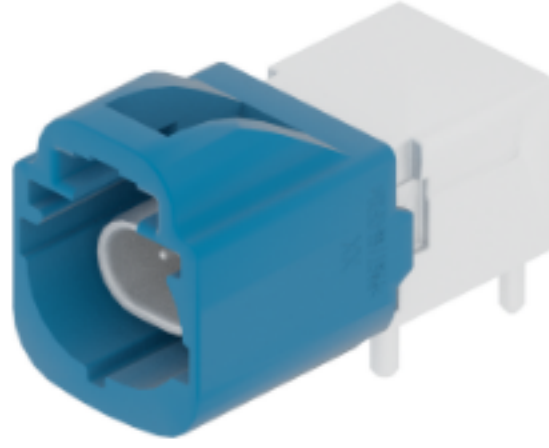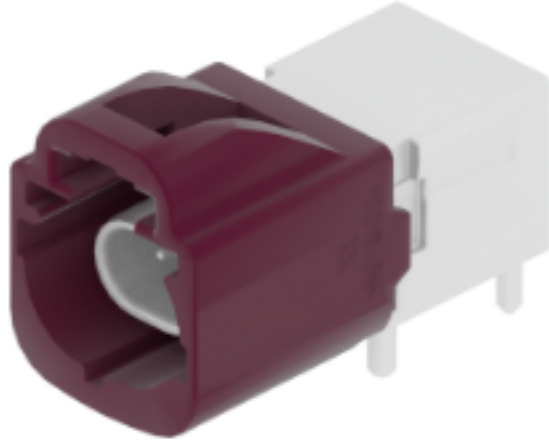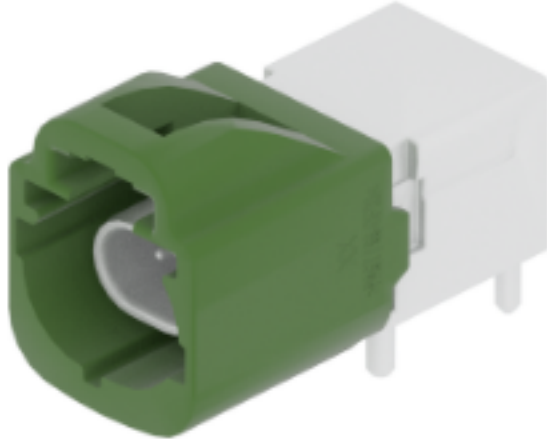

**RESOURCE-CENTER-ITEM**  
COV CONN CLIP CDT BLACK


**35829171**  
2 Way Male 0.5 Unsealed Green

**35829170**  
2 Way Male 0.5 Unsealed Violet

**35829169**  
2 Way Male 0.5 Unsealed Blue



Next Steps

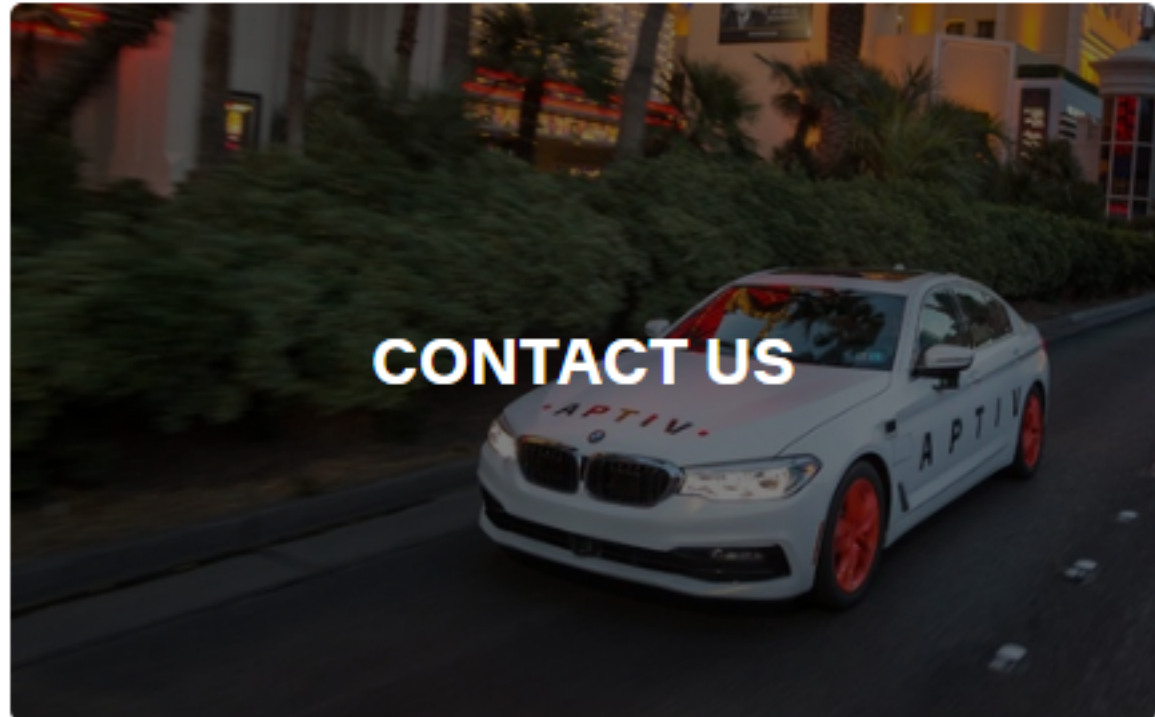

Keep pace with where mobility is going.

See what's next and get the latest updates.

SIGN UP TO GET UPDATES 

Don't worry. We won't flood your inbox or share your email.

INSIGHTS

EXPLORE ALL ARTICLES  
CASE STUDIES  
MOBILITY INSIDER  
RESEARCH PUBLICATIONS  
WHITE PAPERS

SOLUTIONS

Advanced Safety  
Connected Services  
Connection Systems  
Connectivity and Security  
Electrical Distribution Systems  
Middleware & DevOps  
Smart Vehicle Architecture  
User Experience  
Vehicle Electrification Systems  
HellermannTyton  
Intercable Automotive Solutions  
Motional  
Winchester Interconnect  
Wind River

CATALOG

ABOUT

Our Mission  
Our Businesses  
Our Locations  
Our Foundation  
Sustainability  
Suppliers

PRIVACY

Terms of Use  
Cookie Policy

LEGAL & COMPLIANCE

CAREERS

INVESTORS  
NEWSROOM  
CONTACT