

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0640014100

Status:


Active

Overview:

Application Tooling

Description:

PremiumGrade Hand Crimp Tool for Flag Insulkrimp Quick Disconnect Terminals, 14-22AWG

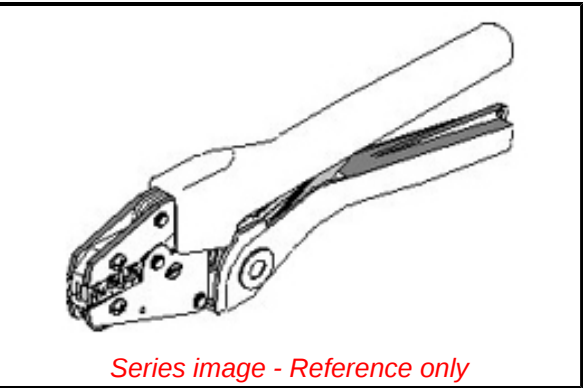

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207129
Comments	Type RHT
Function	Crimp
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Hand Crimp Tool
UPC	822348071067
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Engineering Number

RHT-FIFG

Reference - Drawing Numbers

Application Tooling Documents

ATS-640014100-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per - ED/30/2017 (7 July 2017)

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

207129 Series

Use With

Loose Piece Terminals

Application Tooling Description	FAQ Product #
---------------------------------	---------------

Flag InsulKrimp Quick Disconnect, Female, for 18-22 (0.80-0.35mm ²) Wire, Box, Tab 6.35 x 0.81mm	190070001
Flag InsulKrimp Quick Disconnect, Female, for 18-22 (0.80-0.35mm ²) Wire, Box, Tab 4.75 x 0.51mm	190070009
Flag InsulKrimp Quick Disconnect, Female, for 18-22 (0.80-0.35mm ²) Wire,	190070015

Box, Tab 4.75 x 0.81mm
Flag InsulKrimp 190070021
Quick Disconnect, Female, for 14-16 (2.00-1.30mm²) Wire,
Box, Tab 6.35 x 0.81mm
Flag InsulKrimp 190070029
Quick Disconnect, Female, for 14-16 (2.00-1.30mm²) Wire,
Box, Tab 4.75 x 0.51mm
Flag InsulKrimp 190070035
Quick Disconnect, Female, for 14-16 (2.00-1.30mm²) Wire,
Box, Tab 4.75 x 0.81mm
InsulKrimp Female 190070064
Fully Insulated Quick Disconnect Flag for 18-22 AWG Wire, Tab 6.35 x 0.81mm, 94 V-0 Material
InsulKrimp Female 190070067
Fully Insulated Quick Disconnect Flag for 18-22 AWG Wire, Tab 4.75 x 0.51mm, 94 V-0 Material
InsulKrimp Female 190070070
Fully Insulated Quick Disconnect Flag for 18-22 AWG Wire, Tab 4.75 x 0.81mm, 94 V-0 Material
InsulKrimp Female 190070073
Fully Insulated Quick Disconnect Flag for 14-16 AWG Wire, Tab 6.35 x 0.81mm, 94 V-0 Material
InsulKrimp Female 190070076
Fully Insulated Quick Disconnect Flag for 16-14 AWG Wire, Tab 4.75 x 0.51mm, 94 V-0 Material
InsulKrimp Female 190070079
Fully Insulated Quick Disconnect Flag for 14-16 AWG Wire, Tab 4.75 x 0.81mm, 94 V-0 Material