


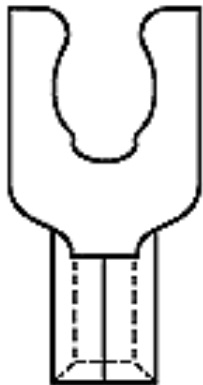

Part Number : [190980017](#)
Product Description : Krimptite Snap Spade
Terminal, for 22-18 AWG Wire, Stud Size 5
(M3), 14.86mm Length
Series Number : 19098
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : AA-1704-05



Documents & Resources

Drawings
[190980017_sd.pdf](#)

3D Models and Design Files
[190980017_stp.zip](#)

Specifications
[PS-19902-011-001.pdf](#)
[PS-19902-013-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements
- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19098
Description	Krimptite Snap Spade Terminal, for 22-18 AWG Wire, Stud Size 5 (M3), 14.86mm Length
Keyword	Spade Terminal, Spade Terminals
Product Name	Krimptite
Type	Spade Snap
UPC	800755081367

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Net Weight	0.432/g
Packaging Type	Bag
Stud Size	5 (M3)
Wire Size (AWG)	18, 20, 22
Wire Size mm ²	0.35-0.80

Application Tooling

Global

Description	Part Number
PremiumGrade Hand Crimp Tool for Krimptite/Versakrimp Terminals and Splices, 22-10 AWG and 6.0mm ² - 0.5mm ²	<u>640030100</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640070100</u>
ServiceGrade Hand Crimp Tool - Ratchet	<u>640160038</u>

This document was generated on Mar 22, 2025