
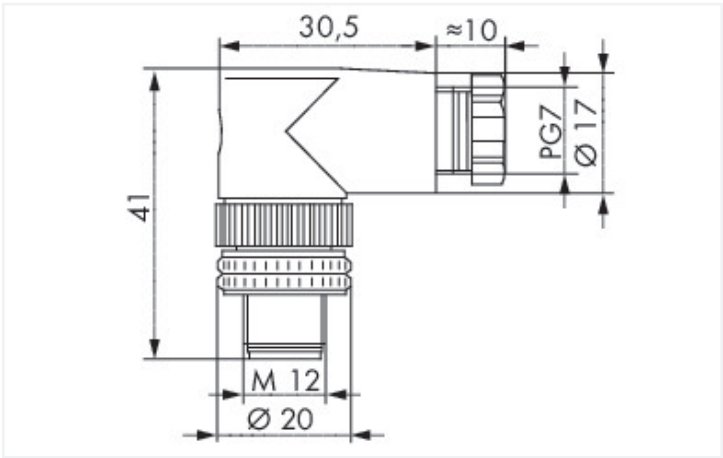


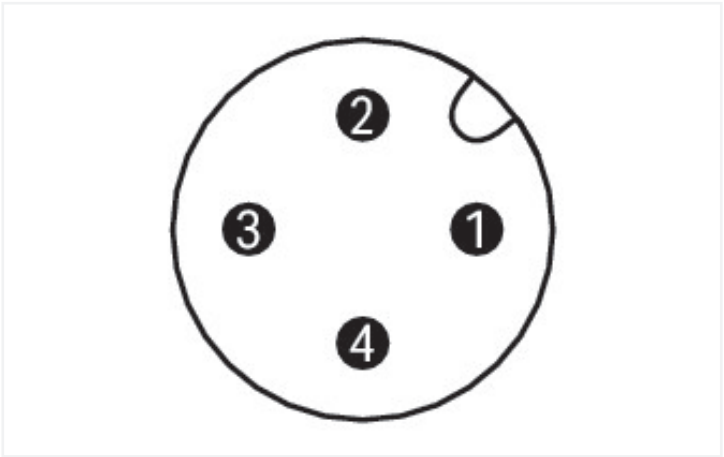

Dimensions in mm

| Technical data                                 |          |
|------------------------------------------------|----------|
| Connection type                                | M12 plug |
| Pole number                                    | 4        |
| Cable connection direction to mating direction | 90 °     |
| Connector interface coding (cable/adapter) 1 1 | A-coded  |
| Contact resistance                             | ≤3 mΩ    |

| Connection data   |                        |
|-------------------|------------------------|
| Connection type 1 | Screw clamp technology |
| Solid conductor   | 0.25 ... 0.75 mm²      |

| Mechanical data                     |                                  |
|-------------------------------------|----------------------------------|
| Connectable sheathed cable diameter | 4 ... 6 mm                       |
| Housing material                    | Polybutylene terephthalate (PBT) |
| Contact material                    | CuZn                             |
| Contact Plating                     | Gold                             |
| Dichtungsmaterial                   | Sealing ring: neoprene           |
| Mating cycles (max.)                | 100                              |
| Weight                              | 26 g                             |



| Environmental requirements      |                 |
|---------------------------------|-----------------|
| Ambient temperature (operation) | -25 ... +85 °C  |
| Protection type                 | IP67            |
| Note on protection type         | in locked state |
| Pollution degree                | 3               |
| Fire load                       | 0 MJ            |

| Commercial data       |               |
|-----------------------|---------------|
| eCl@ss 10.0           | 27-24-26-92   |
| eCl@ss 9.0            | 27-24-26-92   |
| ETIM 8.0              | EC002584      |
| ETIM 7.0              | EC002584      |
| PU (SPU)              | 5 pcs         |
| Packaging type        | Box           |
| Country of origin     | HU            |
| GTIN                  | 4044918977432 |
| Customs tariff number | 85366990990   |

| Environmental Product Compliance |                        |
|----------------------------------|------------------------|
| RoHS Compliance Status           | Compliant,No Exemption |

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance  
756-9204/040-000

↓

| Documentation                         |                  |                  |            |
|---------------------------------------|------------------|------------------|------------|
| System Description                    |                  | Bid Text         |            |
| IP67 Cables and Plug-gable Connectors | pdf<br>157.80 KB | 756-9204/040-000 | 19.02.2019 |
|                                       |                  | xml<br>2.69 KB   | ↓          |
|                                       |                  | 756-9204/040-000 | 20.09.2017 |
|                                       |                  | doc<br>24.00 KB  | ↓          |

CAD/CAE-Data

CAE data

WSCAD Universe  
756-9204/040-000

↓

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: [www.wago.com](https://www.wago.com)