

Cable connector - CA-07S1N8AT006S



1619418

<https://www.phoenixcontact.com/us/products/1619418>

Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.

Cable connector, CA, angled, shielded: yes, SPEEDCON locking, M23, No. of pos.: 7, Direction of rotation: Standard, type of contact: Socket, Crimp connection, cable diameter range: 4 mm ... 6 mm, coding:N



Your advantages

- Angled cable outlet for confined spaces
- Can be adapted to various applications, thanks to adjustable cable outlet direction
- Safe use in the field, thanks to high degree of protection
- Connector for flexible on-site assembly
- Consistent EMC protection for reliable transmission of signals
- Reduced connection time with SPEEDCON fast locking system
- Crimping connection: vibration- and temperature-resistant assembly

Cable connector - CA-07S1N8AT006S



1619418

<https://www.phoenixcontact.com/us/products/1619418>

Commercial Data

Item number	1619418
Packing unit	1 pc
Minimum order quantity	1 pc
Sales Key	A12
Product Key	ABRBFH
Catalog Page	Page 90 (C-2-2019)
GTIN	4046356824293
Weight per Piece (including packing)	187.5 g
Weight per Piece (excluding packing)	187.5 g
Customs tariff number	85366990
Country of origin	DE

Cable connector - CA-07S1N8AT006S



1619418

<https://www.phoenixcontact.com/us/products/1619418>

Technical Data

Notes

Order information:	Order 7 x Ø 2 mm crimp contacts separately
--------------------	--

Product properties

Product type	Circular connector (cable-side)
--------------	---------------------------------

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

Connector

Insulating body

Application	Signal
Number of positions	7
Contact type	Socket
Coding	N
Connection method	Crimp connection
Connection profile	7
Direction of rotation	Standard
Material	PA 6.6

Housing

Type of locking	SPEEDCON locking
Thread type	M23
Degree of protection	IP67
Housing material	Metal
Seal material	NBR
External cable diameter	4 mm ... 6 mm

Cable connector - CA-07S1N8AT006S


1619418

<https://www.phoenixcontact.com/us/products/1619418>



Drawings

Dimensional drawing

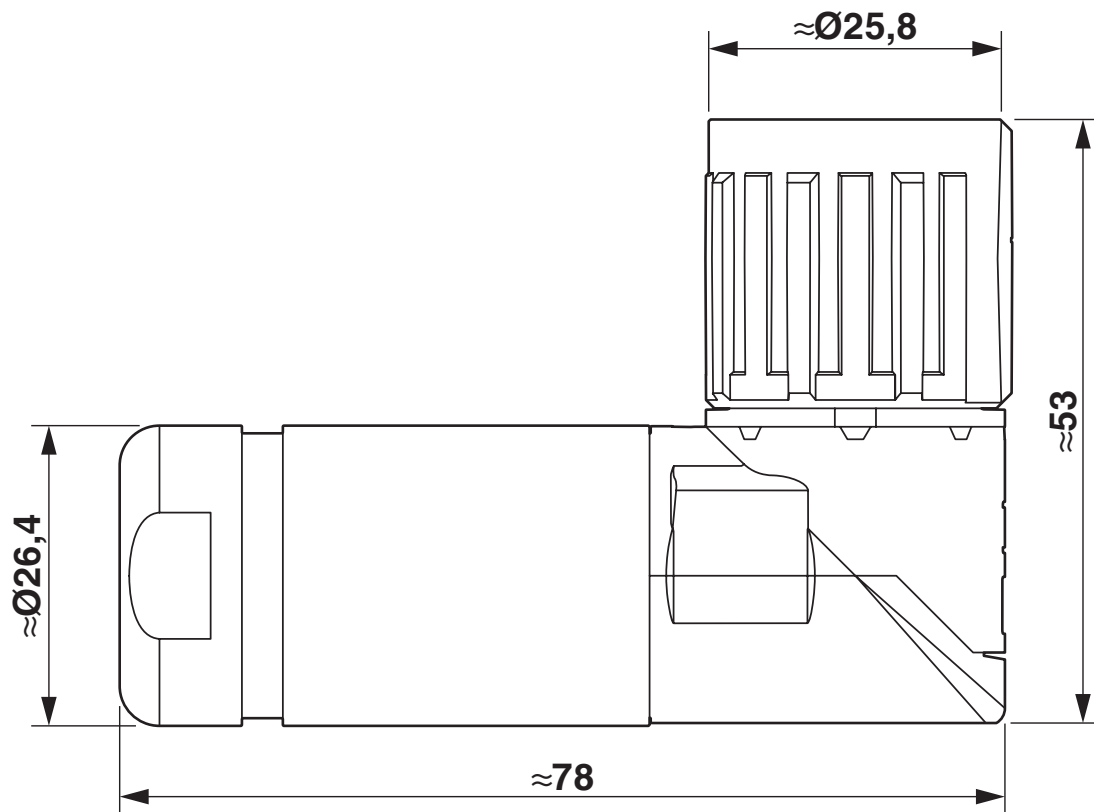

Cable connector - CA-07S1N8AT006S



1619418

<https://www.phoenixcontact.com/us/products/1619418>

Approvals

cUL Recognized Approval ID: E335019-20141210				
	Nominal Voltage U _N	Nominal Current I _N	Cross Section AWG	Cross Section mm ²
	48 V	10 A	- 14	-

UL Recognized Approval ID: E335019-20141210				
	Nominal Voltage U _N	Nominal Current I _N	Cross Section AWG	Cross Section mm ²
	48 V	17 A	- 14	-

cULus Recognized				
------------------	--	--	--	--

Cable connector - CA-07S1N8AT006S



1619418

<https://www.phoenixcontact.com/us/products/1619418>

Classifications

ECLASS

ECLASS-9.0	27440102
ECLASS-10.0.1	27440102
ECLASS-11.0	27440102

ETIM

ETIM 8.0	EC002635
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

Cable connector - CA-07S1N8AT006S



1619418

<https://www.phoenixcontact.com/us/products/1619418>

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
China RoHS	Environmentally Friendly Use Period = 50 years
	For information on hazardous substances, refer to the manufacturer's declaration available under "Downloads"

Cable connector - CA-07S1N8AT006S



1619418

<https://www.phoenixcontact.com/us/products/1619418>

Accessories

Protective cap

Protective cap - RC-Z2058 - 1604223

<https://www.phoenixcontact.com/us/products/1604223>

Plastic protection cap for connectors with M23 knurled nut



Plastic anti-static dust protection cap

Plastic anti-static dust protection cap - RC-Z2468 - 1611796

<https://www.phoenixcontact.com/us/products/1611796>

Plastic protection cap, antistatic, for connectors with M23 knurled nut



Cable connector - CA-07S1N8AT006S

1619418

<https://www.phoenixcontact.com/us/products/1619418>



Torque screwdriver

Torque screwdriver - SF-Z0028 - 1607456

<https://www.phoenixcontact.com/us/products/1607456>

Torque screwdriver, series: RC



Hook wrench

Hook wrench - SF-Z0027 - 1607455

<https://www.phoenixcontact.com/us/products/1607455>

Hook wrench, series: RC



Cable connector - CA-07S1N8AT006S



1619418


<https://www.phoenixcontact.com/us/products/1619418>

Color-coding

Color-coding - RF-Z0014 - 1620588

<https://www.phoenixcontact.com/us/products/1620588>

Color-coding, color: green

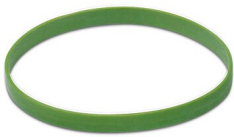

Color-coding

Color-coding - RF-Z0015 - 1620592

<https://www.phoenixcontact.com/us/products/1620592>

Color-coding, color: orange



Cable connector - CA-07S1N8AT006S



1619418

<https://www.phoenixcontact.com/us/products/1619418>

Color-coding

Color-coding - RF-Z0016 - 1620593

<https://www.phoenixcontact.com/us/products/1620593>

Color-coding, color: black



Crimp contact

Crimp contact - RC-5CS2000 - 1603517

<https://www.phoenixcontact.com/us/products/1603517>

Crimp contact, turned, contact diameter: 2 mm, crimp range: 1 mm² ... 1.5 mm²



Cable connector - CA-07S1N8AT006S



1619418

<https://www.phoenixcontact.com/us/products/1619418>

Crimp contact

Crimp contact - RC-5AS2000 - 1603509

<https://www.phoenixcontact.com/us/products/1603509>



Crimp contact, turned, contact diameter: 2 mm, crimp range: 1.5 mm² ... 2.5 mm²

Crimp contact

Crimp contact - RC-59S2000 - 1603501

<https://www.phoenixcontact.com/us/products/1603501>



Crimp contact, turned, Single contact, contact diameter: 2 mm, crimp range: 0.75 mm² ... 1 mm²

Cable connector - CA-07S1N8AT006S



1619418

<https://www.phoenixcontact.com/us/products/1619418>

Crimp contact

Crimp contact - RC-5SS2000 - 1603530

<https://www.phoenixcontact.com/us/products/1603530>



Crimp contact, turned, contact diameter: 2 mm, crimp range: 0.5 mm² ... 0.75 mm²

Phoenix Contact 2022 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA

586 Fulling Mill Road

Middletown, PA 17057, United States

(+717) 944-1300

info@phoenixcon.com