


RoHS
Compliant

VERSION	DESCRIPTION	DATE
1.0	New Release	2018/4/12

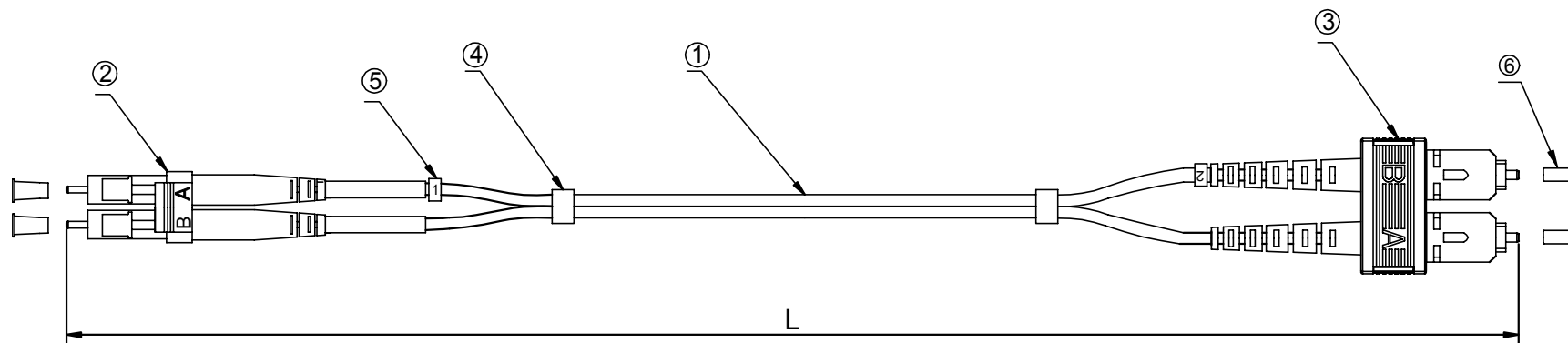

PART NO	DRAWING NO	CABLE LENGTH "L"	COLOR
912S-2-5-00100	671-460-A	1000±100	Yellow
912S-2-5-00200	671-460-B	2000±100	Yellow
912S-2-5-00300	671-460-C	3000±100	Yellow
912S-2-5-00500	671-460-D	5000±100	Yellow
912S-2-5-00700	671-460-E	7000±100	Yellow
912S-2-5-01000	671-460-F	10000±100	Yellow
912S-2-5-01500	671-460-G	15000±100	Yellow
912S-2-5-02000	671-460-H	20000±100	Yellow
912S-2-5-02500	671-460-I	25000±100	Yellow

NOTES:

Insertion loss < 0.3 dB
Return loss > 50 dB

6	Dust Cover
5	¹ / ₂ Code
4	Shrinkage Tube
3	SC SM Duplex Connector (Blue housing Blue boot)
2	LC SM Duplex Connector (Blue housing White boot)
1	2.0mm,Duplex,SM-9/125 G652D, PVC, Optical Fiber Cable(Yellow)
No.	Description

CnC Tech, LLC
Industrial Cable and Connector Technology

		TITLE		Patch Cord, LC-SC,SM-9/125 G652D, Duplex, PVC, yellow, 2.0mm, xxm	
UNIT		mm		P/N	DRAWN BY
unless otherwise stated Tolerances mm XXX.XX ±0.3 ±2° XX.XX ±0.2 X.XX ±0.1		Customer P/N		912S-2-5-0xxxx	CHECK BY
SIZE		SCALE		PAGE	1/1
A4		Free		APPROVAL BY	