


### C5A06UXXX

(M12 Cordset, 5 Position, 22 AWG Shielded, Male Straight to Free End)

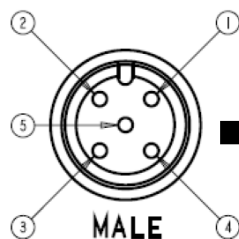

Pin Out		
End 1	Color	End 2
1	Brown	Free End
2	White	
3	Blue	
4	Black	
5	Grey	

- Mueller's C5A05UXXX is an M12 5-pin single ended, shielded instrumentation cable with a straight male connector on one end and free at the other.
- Keyway – A Coding
- Utilizes a 5-conductor 22 AWG PVC-insulated, shielded cable.
- Ratings:
  - Current: 4 A
  - Voltage: 250 V AC/DC
- Material:
  - Coupling Nuts – Nickel Plated Brass
  - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement. Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68

Mueller Electric Company  
2850 Gilchrist Rd. Bld 5A  
Akron, OH 44305

[www.muellerelectric.com](http://www.muellerelectric.com)

Toll Free: 800.955.2629  
Phone: 330.780.2525  
Fax: 330.780.2524

- RoHS 3 Compliant

Mueller Electric Company  
2850 Gilchrist Rd. Bld 5A  
Akron, OH 44305

[www.muellerelectric.com](http://www.muellerelectric.com)

Toll Free: 800.955.2629  
Phone: 330.780.2525  
Fax: 330.780.2524