


COIL: @ 25° C  
 RESISTANCE 160 OHMS ± 10%  
 NOMINAL VOLTAGE 12.0 VDC  
 MUST OPERATE 6.4 VDC  
 MUST RELEASE .7 VDC

CUSTOMER DATA SHEET

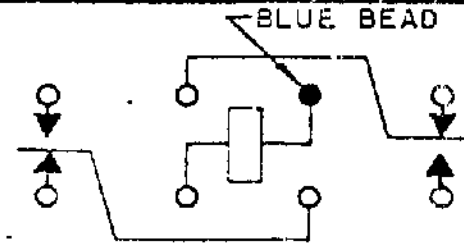

ENVIRONMENT:  
 VIBRATION 10 CPS TO 2000 CPS AT 20 g's  
 SHOCK 100 g's 6 ± 1 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

CONTACT RATING: LOW LEVEL TO  
2 A @ 28 VDC

NOTES:  
 \_\_\_\_\_  
 \_\_\_\_\_  
 \_\_\_\_\_

DR. 1-23-84 CK. OSW



CUST. CII STD  
 CUST. NO. \_\_\_\_\_

TYPE HFW RELAY

HFW 1201G00