

Data Sheet | Item Number: 211-861

Conductor markers for thread-on mounting; for Smart Printer; 5 x 10.5 mm; white

<https://www.wago.com/211-861>



Color: ■ white

Similar to illustration

Technical data

Suitable	for wire cross-section 0.75 ... 1.5 mm ²
Marking method	Thermal transfer
Marking	plain
Delivery form	Roll
Delivery form configuration	1000 pcs/reel; 3 lines
Printing device	Smart Printer (thermal transfer printer)

Physical data

Depth	0.22 mm
Marking surface	5 x 23 mm

Mechanical data

Mounting type	Sliding on conductor
Smear resistance	in conjunction with 258-5005 Ink Ribbon

Material data

Color	white
Material	Polyester
UV resistance	EN 60068-2-5:2010 Procedure B
Adhesive information	without adhesive
Halogen-free	Yes
Weight	165 g
Fire load	0 MJ



Environmental requirements	
Ambient temperature (operation)	-40 ... +150 °C
Relative humidity	40 ... 50 %

Commercial data	
Product Group	2 (Terminal Block Accessories)
PU (SPU)	1 pcs
Packaging type	Box
Country of origin	DE
GTIN	4050821688655
Customs tariff number	39269097900


Product classification	
UNSPSC	55121612
eCl@ss 10.0	27-40-04-01
eCl@ss 9.0	27-40-06-29
ETIM 9.0	EC001530
ETIM 8.0	EC001530
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Downloads	
Environmental Product Compliance	
Compliance Search	
Environmental Product Compliance 211-861	

Documentation	
Operating Instructions	
211-861 Information on printing material	128.08.2020pdf1244.38 KB

Installation Notes	
Application	

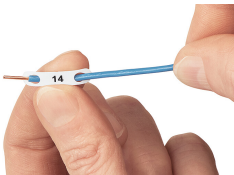

Conductor marker for thread-on mounting

Subject to changes. Please also observe the further product documentation!

Current addresses can be found at: www.wago.com