
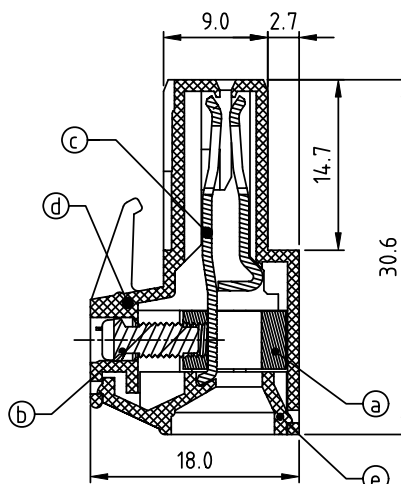
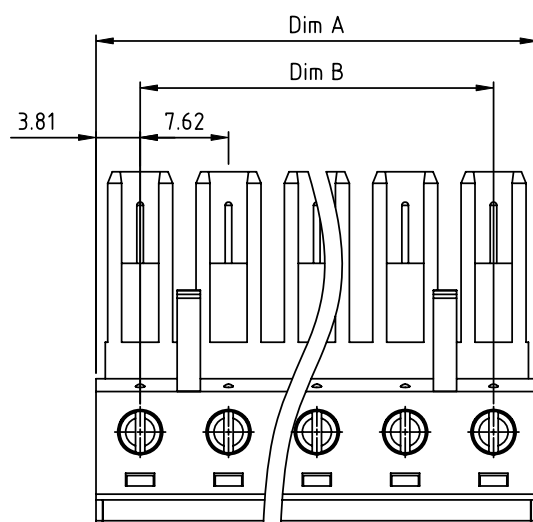
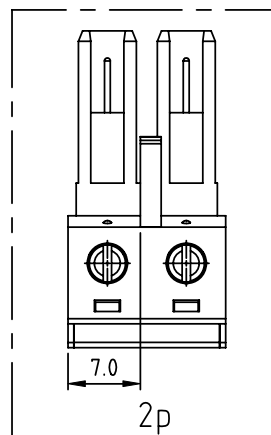


PRODUCT NUMBER	PITCH
VBxx01x000J0G	7.62 mm

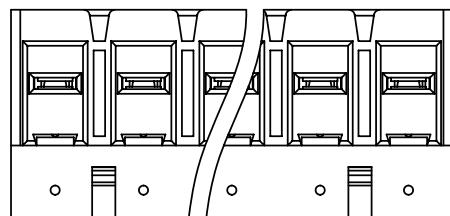

Material

- Item④Clamp : Copper alloy Ni plated
- Item⑤Terminal screw:SteelZinc plating“-“slot type
- Item⑥Female contact : Copper Tin plated
- Item⑦Terminal (body):Thermoplastic (UL94 V-0)
- Item⑧Terminal (cover):Thermoplastic (UL94 V-0)

Electrical cULus

- Voltage rating: 300V
- Current rating: 20A
- Wire range:
- Solid wire(AWG):10-30
- Stranded wire(AWG):10-30
- Torque: 4.5(Lb-In)
- Screw:M3
- Wire strip length:7-8mm
- Withstanding Voltage:1.6KV
- Operating temperature:-40°C to +115°C
- Safety Approval: us

PART NO.: VB xx 01 x 0 00J0 G

N = Number of poles

$$\text{Dim } A = N \times 7.62$$
$$\text{Dim } B = (N-1) \times 7.62$$

poles	Tolerance
2-6p	± 0.20
7-12p	± 0.30
13-16p	± 0.40

Solid block	
No. of poles	
02	2 poles
03	3 poles
...	...
16	16 poles

	Color
0	Black (RAL9005)
2	Red (RAL3001/D)
3	Orange(RAL2011/P)
4	Yellow(RAL1018/A)
5	Green(RAL6018/T)
6	Blue (RAL5015/A)
8	Grey(RAL7035/D)
9	White(RAL1102)
C	Green(RAL6018/U)

RoHS compliant
(lead<4%)
In copper Alloy

[illegible]