


OD9238-IP69K Series



DC Fan - 24V, 48V
92x38mm (3.62"x1.5")

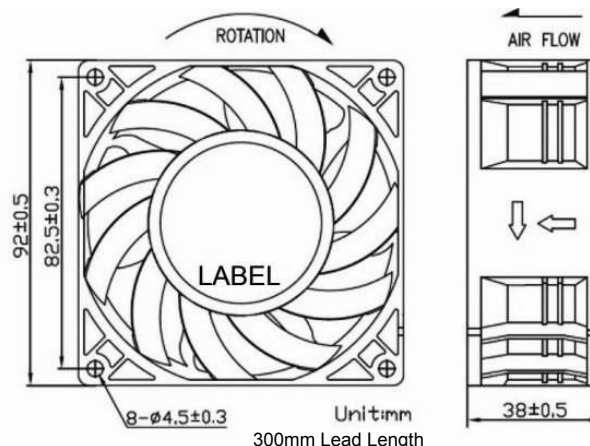

Frame	PBT, UL94 V-0 plastic	<u>Operating Temperature</u> -20°C ~ +65°C	
Impeller	PBT, UL94 V-0 plastic	<u>Storage Temperature</u> -20°C ~ +75°C	
Connection	2x Lead Wires, 24 AWG, 300MM	<u>Life Expectancy</u> 60,000 hours (L10 at 45°C)	
Motor	Brushless DC, Auto Restart, Auto Cutoff, Polarity Protected, Electronically Protected, IP68	<u>Available Options</u> Tachometer Alarm PWM 5V	
Bearing System	Dual Ball Bearings	Weight: 0.44 lbs	
Dielectric Strength	500VAC/min	m0	
Insulation Resistance	10M ohm between leadwires and frame (500 VDC)		

Part Number	Rated Voltage	Input Power	Rated Current	Rated Speed (RPM)	Airflow (CFM)	Noise Level (dB)	Max. Static Pressure
OD9238-24HBIP69K	24 VDC	9.6 W	0.4 A	4500	100	56	0.7" H ₂ O
OD9238-48HBIP69K	48 VDC	12 W	0.25 A	4500	100	56	0.7" H ₂ O