

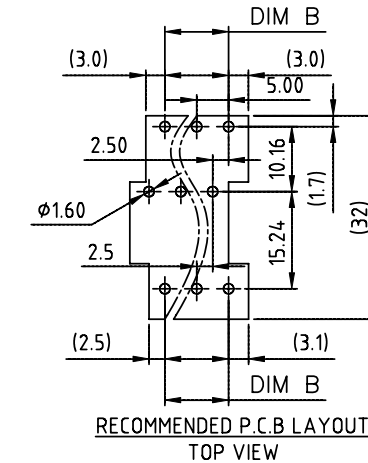
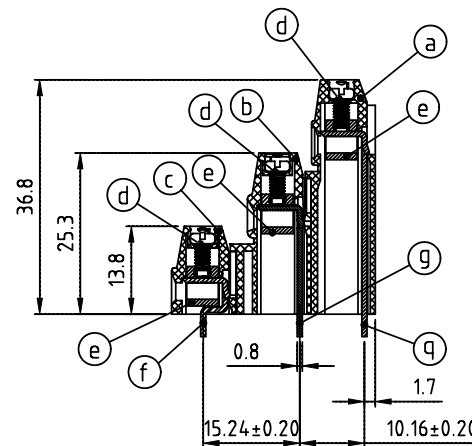


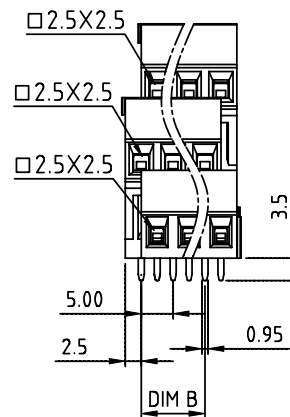

- Item④Terminal housing : Thermoplastic (UL 94V-0)(YF5.0)
- Item⑤Terminal housing : Thermoplastic (UL 94V-0)(YE5.0)
- Item⑥Terminal housing : Thermoplastic (UL 94V-0)(YD5.0)
- Item⑦Terminal screw: Steel Zinc plating"-slot type
- Item⑧Clamp : Brass ,Ni plated
- Item⑨Solder pin1 : Brass ,Tin plated
- Item⑩Solder pin2 : Brass ,Tin plated
- Item⑪Solder pin3 : Brass ,Tin plated

● Safety Approval:  CRUS

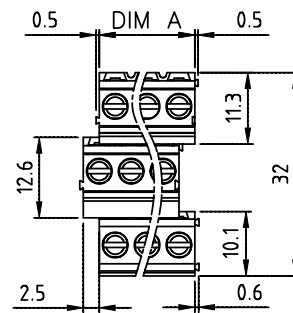

DIM A	$N/3 \times 5.0$
DIM B	$(N/3 - 1) \times 5.0$

Poles	DimA&B Tolerance
3x2P-3x8P	±0.15
3x9P-3x14P	±0.25
3x15P-3x20P	±0.35
3x21P-3x24P	±0.40

End stackable	
No. of poles	
06	3×2poles
09	3×3poles
...	...
72	3×24poles

	Color
0	Black (RAL9005)
2	Red (RAL3001/D)
3	Orange(RAL2011/P)
4	Yellow(RAL1018/A)
5	Green(RAL6018/T)
6	Blue (RAL5015/A)
8	Grey(RAL7035/D)
9	White(RAL1102)
C	Green(RAL6018/U)

RoHS compliant
(lead<4%)
In copper Alloy

[illegible]