

Part Number : [190840007](#)


Product Description : VibraKrimp Open Barrel Star Ring, Tin-Plated Steel, for 18-14 AWG Wire Range, Stud Size 6 (M3.5)

Series Number : 19084

Status : Active

Product Category : Ring and Spade Terminals

Engineering Part Number : SRZ-S-4129-06

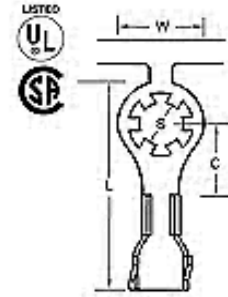

Documents and Resources

Drawings

[190840007_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

Specifications

[PS-19902-006-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19084
Description	VibraKrimp Open Barrel Star Ring, Tin-Plated Steel, for 18-14 AWG Wire Range, Stud Size 6 (M3.5)
Keyword	Ring Terminal, Ring Terminals
Product Name	VibraKrimp
Style	Ring
Type	Ring Terminal, Metric Ring Terminal
UPC	800755080216

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Open
Insulation	None
Material - Plating Mating	Tin
Net Weight	0.801/g
Packaging Type	Reel
Stud Size	6 (M3.5)

Termination Interface Style	Crimp or Compression
Wire Size (AWG)	14, 16, 18
Wire Size mm ²	0.80-2.00

Application Tooling

Global

Description	Part Number
Mini-Mac Applicator	<u>638815600</u>

This document was generated on Dec 30, 2025