



SJA1110AEL

Qualification

Part is not yet fully qualified by NXP to be production ready. May be able to provide samples for customer qualification


Features

Safe and secure TSN Ethernet switch.

Package

LFBGA256

LFBGA256, plastic low profile fine-pitch ball grid array; 256 terminals.

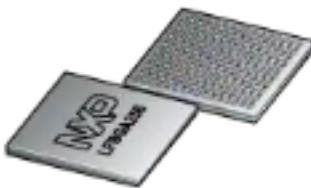

- Buy Options
- Operating Features
- Environmental
- Quality
- Shipping
- Product Change Notice

Buy Options

SJA1110AEL/0Y

12NC: 935375664518

Qualification

Packing: REEL-Reel 13" Q1/T1 in Drypack

Min. Package Quantity: 1000

Min. Order Quantity: 1000

Lead Time: 52

> Available Distributors: SJA1110AEL/0Y

BUY FROM DISTRIBUTOR

Operating Features

No information available

Environmental

Part/12NC	PbFree	EU RoHS	Halogen Free	RHF Indicator	REACH SVHC	Weight (mg)
SJA1110AEL/0Y(935375664518)	Yes	Yes	Yes	D	REACH SVHC	531.029706843079

Quality

Part/12NC	Safe Assure Functional Safety	Moisture Sensitivity Level (MSL)	Peak Package Body Temperature (PPT) (C°)		
		Lead Free Soldering	Lead Soldering	Lead Free Soldering	
SJA1110AEL/0Y (935375664518)	ISO 26262	3	240	260	

Shipping

Part/12NC	Harmonized Tariff (US) Disclaimer	Export Control Classification Number (US)	CCATS
SJA1110AEL/0Y (935375664518)	854231	5A991	-

Product Change Notice

Part/12NC	Issue Date	Effective Date	PCN	Title
SJA1110AEL/0Y (935375664518)	2020-12-15	2020-12-16	202011011I	NXP Will Add a Sealed Date to the Product Label

News May 13, 2022 | NXP Extends Exchange Offers [Read More](#)

