

## G80-1800



Models may vary from the image shown

### Small dimensions and top performance!

Standard? Yes! Boring? No - the compact design of the 19 inch PC keyboard is highly distinctive. For space-saving applications and optimum longevity requirements.

### Key benefits

- Individual keys with Gold Crosspoint contacts (MX technology)
- Codeset 3 support (PS/2 connection only) e.g. for Unix computers
- Perfect key feeling
- High quality and compact 19" PC keyboard - space-saving and ergonomic
- High-quality keyboard for outstanding writing performance, fulfilling even the highest demands
- Extremely high service life of individual keys

### Technical Data:

#### Layout (country or language):

Product dependant, see table "Models"

#### Housing colour:

Product dependant, see table "Models"

#### Key colour:

Product dependant, see table "Models"

#### Weight (product):

approx. 920 g

#### Total weight (with packaging):

approx. 1190 g

#### Cable Length:

approx. 1.75 m

#### Storage Temperature:

-20°C to 60°C

#### Operating Temperature:

0°C to 50°C

#### Current Consumption:

typ. 16 mA

#### Interface:

- USB (PS/2 via adapter)

#### Product approvals:

- cURus
- CE
- FCC
- VDE



#### System requirements:

- USB or PS/2 connection

#### Delivery Volume:

- G80-1800
- Printed instructions

#### Dimensions (product):

approx. 405 x 180 x 44 mm

#### Packaging dimensions:

approx. 460 x 270 x 50 mm

#### Keyboard:

- Key technology: MX
- Service life, standard key: > 50 million key operations
- Operation characteristics: Product dependant, see table "Models"
- Inscription technology: Laser
- Inscription layout: Standard
- Number of Keys: Product dependant, see table "Models"

#### Packaging Unit:

- Number of products in the master package: 18
- Number of master packages per pallet: 6

#### Warranty:

3-year limited manufacturer's guarantee

For the first two years after delivery, the statutory warranty applies. In the third year after delivery, CHERRY voluntarily grants an additional warranty according to the following conditions ("extended warranty"). In the event of a defect, please contact the seller of your CHERRY product. Do not carry out any repairs on your own and do not open the product. There is no warranty if unauthorized changes to the product cause a defect.

Conditions for the extended warranty:

In the case of a defect after the first 2 years after delivery of the CHERRY product, CHERRY grants its customers for the additional period of one year the right to assert claims for cure, i.e. demand that the defect is remedied or a thing free of defects is supplied. The extended warranty is to be asserted against the seller of the CHERRY product upon presentation of the original invoice, proof of purchase or a comparable proof of the time of purchase.

CHERRY, and the seller of the CHERRY product, where applicable, shall remedy the defect in the event the customer has justified claims for cure under the terms of the extended warranty.

Excluded from the extended warranty are damages caused by improper use, in particular by the effects of chemical substances, other damages caused by external influences, as well as normal wear and tear and optical changes, in particular discoloration or abrasion of shiny areas. Also excluded from the extended warranty are accessories and other parts which are not an integral part of the purchased item.

Errors, technical changes and delivery possibilities excepted. Technical information refers only to the specifications of the products. Features may differ from the information provided.
---

## Models:


(possible country/layout versions, others available on request)

	Product name	Order number	EAN code	Layout (country or language)	Housing colour	Key colour	Operation characteristics <sup>1</sup>	Number of Keys
1	G80-1800	G80-1800LPCCH-0	4025112066467	Switzerland	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
2	G80-1800	G80-1800LPCDE-0	4025112064968	Germany	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
3	G80-1800	G80-1800LPCDE-2	4025112065040	Germany	black	black	BLACK SWITCH Linear (60 cN)	105
4	G80-1800	G80-1800LPCDK-0	4025112073342	Denmark	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
5	G80-1800	G80-1800LPCES-0	4025112072000	Spain	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
6	G80-1800	G80-1800LPCEU-0	4025112064937	US English with EURO symbol	light grey	light grey	BLACK SWITCH Linear (60 cN)	104
7	G80-1800	G80-1800LPCEU-2	4025112064975	US English with EURO symbol	black	black	BLACK SWITCH Linear (60 cN)	104
8	G80-1800	G80-1800LPCFR-0	4025112064951	France	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
9	G80-1800	G80-1800LPCGB-0	4025112064944	UK	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
10	G80-1800	G80-1800LPCGB-2	4025112072031	UK	black	black	BLACK SWITCH Linear (60 cN)	105
11	G80-1800	G80-1800LPCIT-0	4025112073335	Italy	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
12	G80-1800	G80-1800LPCPO-0	4025112072017	Portugal	light grey	light grey	BLACK SWITCH Linear (60 cN)	105
13	G80-1800	G80-1800LPCRB-0	4025112072024	English (US) / Cyrillic	light grey	light grey	BLACK SWITCH Linear (60 cN)	104
14	G80-1800	G80-1800LPCSF-0	4025112073359	Sweden / Finland	light grey	light grey	BLACK SWITCH Linear (60 cN)	105


	Product name	Order number	EAN code	Layout (country or language)	Housing colour	Key colour	Operation characteristics <sup>1</sup>	Number of Keys
15	G80-1800	G80-1800LWCKO-2	4025112068829	Korea	black	black	BLUE SWITCH Click pressure point (60cN)	104
16	G80-1800	G80-1800LXCKO-2	4025112068836	Korea	black	black	BROWN SWITCH Pressure point (55cN)	104

## 1 Operation characteristics:

### • BLACK SWITCH Linear (60 cN)

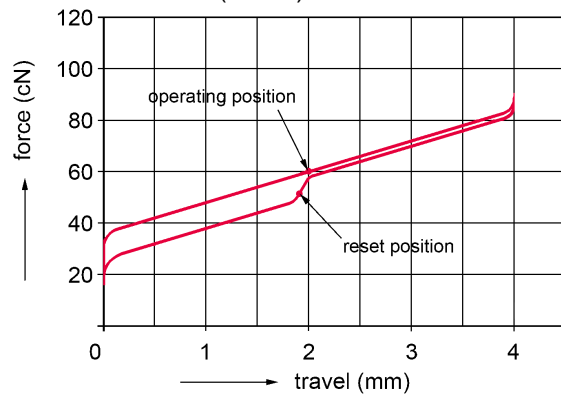

### • BLUE SWITCH Click pressure point (60cN)

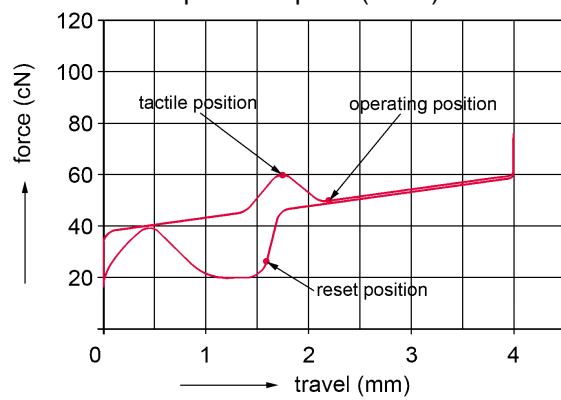

### • BROWN SWITCH Pressure point (55cN)

