


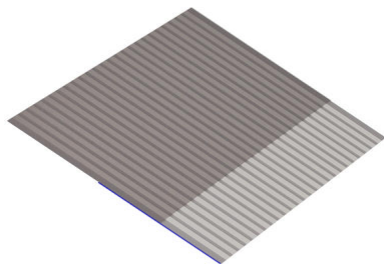

**Part Number :** [151660963](#)  
**Product Description :** 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 305.00mm Cable Length, Tin (Sn) Plating, 25 Circuits  
**Series Number :** 15166  
**Status :** Active  
**Product Category :** Flat-Flexible Cable (FFC)



## Documents and Resources

### Drawings

- [151660963 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

### Specifications

- [PS-15166-001-001.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                                                                         |
|--------------------|---------------------------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                                            |
| China RoHS         |  per SJ/T 11365-2006 |
| EU ELV             | Not Relevant                                                                                            |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21                                                                          |
| REACH SVHC         | Not Contained per D(2023)8585-DC (23 Jan 2024)                                                          |
| EU RoHS            | Compliant per EU 2015/863                                                                               |

### [Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

### [Industry Documents](#)

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

---

**Part Details**

**General**

|              |                                                                                                                       |
|--------------|-----------------------------------------------------------------------------------------------------------------------|
| Status       | Active                                                                                                                |
| Category     | Flat-Flexible Cable (FFC)                                                                                             |
| Series       | 15166                                                                                                                 |
| Description  | 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 305.00mm Cable Length, Tin (Sn) Plating, 25 Circuits |
| Comments     | Contacts on the same side, Type A                                                                                     |
| Product Name | Premo-Flex FFC Jumper                                                                                                 |
| UPC          | 884982922655                                                                                                          |

**Electrical**

|                               |        |
|-------------------------------|--------|
| Current - Maximum per Contact | 0.35A  |
| Voltage - Maximum             | 60V AC |

**Physical**

|                           |                |
|---------------------------|----------------|
| Cable Length              | 305.00mm       |
| Circuits (Loaded)         | 25             |
| Contact Layout Type       | A (same side)  |
| Design Feature            | Ultra-Flexible |
| Material - Plating Mating | Tin            |
| Net Weight                | 1.000/g        |
| Packaging Type            | Bag            |
| Pitch - Mating Interface  | 0.50mm         |

|                               |                           |
|-------------------------------|---------------------------|
| Temperature Range - Operating | -40° to +105°C            |
| Termination Style             | FFC Connector             |
| Wire/Cable Type               | Flat Flexible Cable (FFC) |
| Wire Size (AWG)               | N/A                       |

---

## Mates With / Use With

### Mates with Part(s)

| Description                                                                                                                                                 | Part Number                      |
|-------------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------|
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 25 Circuits, Tin-Bismuth Plating                        | <a href="#"><u>524372572</u></a> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 25 Circuits, Tin-Bismuth Plating                                           | <a href="#"><u>525592570</u></a> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Tin Bismuth Plating, Short Terminal Type, Black, 25 Circuits | <a href="#"><u>781192510</u></a> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Tin Bismuth Plating, Long Terminal Type, Black, 25 Circuits   | <a href="#"><u>781272510</u></a> |

---

This document was generated on May 20, 2026