


Connectorsfor Automobiles

Connect with the Best

⚠ How to choose connectors⚠ Notes on usage📄 Catalogue PDF

results

Product information

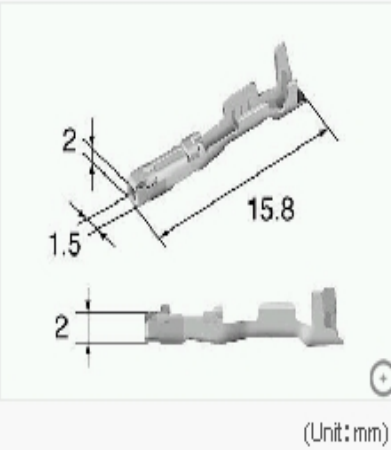

(Unit:mm)

Contact us for products

8100-3456

TS sealed series

Terminal

For AV Wire


0.64mm(025)

Sealed/Unsealed	sealed
Male/Female	F
Tab Size	0.64mm(025)
Size	M
Mating parts	<u>8100-3708</u> (TS sealed series)


Applicable wire size	0.22-0.35mm ²
Materials	Heat-resistant copper alloy
Surface treatment	Gold-plated
Contact resistance	Initial8mΩ Max. after durability tests16mΩ Max.
Leak current	50μA Max.
Insulation resistance	100MΩ Min.

TS sealed series 0.64mm(025) related products


▶ Housing (31)

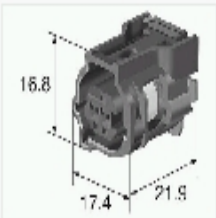

0.64mm 6189-1161

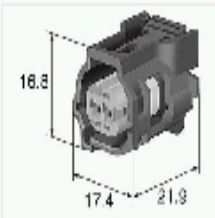

0.64mm 6189-7020

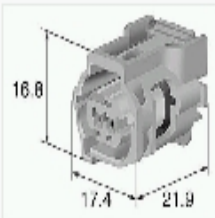


0.64mm 6189-7073




0.64mm 6189-1129

Show all results


▶ Wire seals (5)

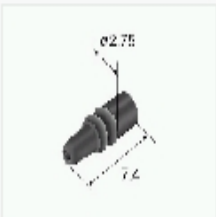


0.64mm 7165-1043

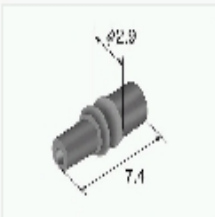

0.64mm 7165-1312

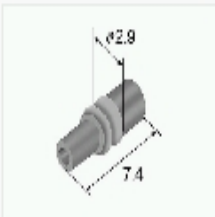

0.64mm 7165-1198

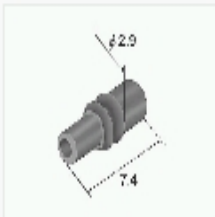

0.64mm 7165-1199

Show all results