

[»Back to Board Level Products](#)

## 2207PR11BASSYG

TO-5



Two piece heat sink



**Height:** 9.14

**Mount Orientation:** Horizontal

**Finish:** Black Anodize

**RoHS:** compliant

**Thermal Resistance:** 41.00

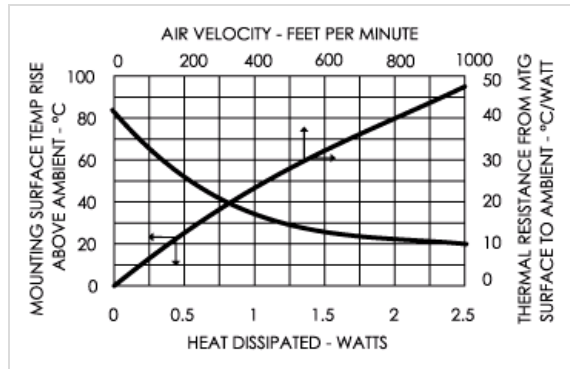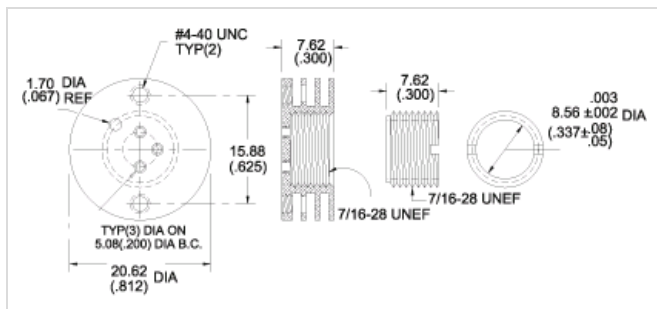

### Need assistance?

Call us: 1-855-32-AAVID  
Email: [estore@aavid.com](mailto:estore@aavid.com)

[» Help Page](#)

### Check Distributor Stock

Enter a part number for  
pricing and availability.

[>Request a Sample](#)  
[>Request a Quote](#)  
[>Ask an Engineer](#)

### The Fine Print

[Product Return Policy](#)  
[Terms & Conditions](#)  
[Privacy Policy](#)

### Customer Assistance

- [Contact Us](#)
- [Get Design Assistance](#)
- [Find a Distributor](#)
- [Find a Sales Rep](#)
- [Request a Quote](#)
- [Placing an Order](#)
- [Terms and Conditions](#)
- [Returns](#)

### Popular Products

- [Fans](#)
- [Extrusions](#)
- [Board Level](#)
- [Liquid Cooling](#)
- [Heat Pipe Technology](#)
- [Heat Sink Accessories](#)
- [Interface Materials](#)

### Our Company

- [News and Events](#)
- [Management Team](#)
- [Worldwide Locations](#)
- [Directions to Headquarters](#)
- [Disclaimer](#)
- [Customer Survey](#)
- [Privacy Policy](#)

### Connect with Aavid

Sign up for Aavid News & Alerts

Like / Follow / Connect



© Copyright 2015 Aavid Thermalloy, LLC.