

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [49517-0500](#)  
**Status:** **Active**  
**Description:** 3.96mm Pitch Wire-to-Board Female Housing, 5 Circuits, Natural

**Documents:**

[3D Model](#)  
[Drawing \(PDF\)](#)  
[Product Specification PS-49517-001 \(PDF\)](#)  
[Packaging Specification PK-49517-001 \(PDF\)](#)  
[RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

UL E29179

**General**

Product Family Crimp Housings  
Series [49517](#)  
Application Power, Wire-to-Board  
Product Name N/A  
UPC 822350016407

**Physical**

Breakaway No  
Circuits (maximum) 5  
Color - Resin Natural  
Flammability 94V-0  
Gender Female  
Glow-Wire Compliant No  
Keying to Mating Part None  
Lock to Mating Part None  
Material - Resin Nylon  
Net Weight 0.989/g  
Number of Rows 1  
Packaging Type Bag  
Panel Mount No  
Pitch - Mating Interface 3.96mm  
Polarized to Mating Part Yes  
Stackable No  
Temperature Range - Operating -25°C to +85°C


**Electrical**

Current - Maximum per Contact 7A

**Material Info**

**Reference - Drawing Numbers**

[Packaging Specification](#) PK-49517-001  
[Product Specification](#) PS-49517-001  
[Sales Drawing](#) SD-49517-001

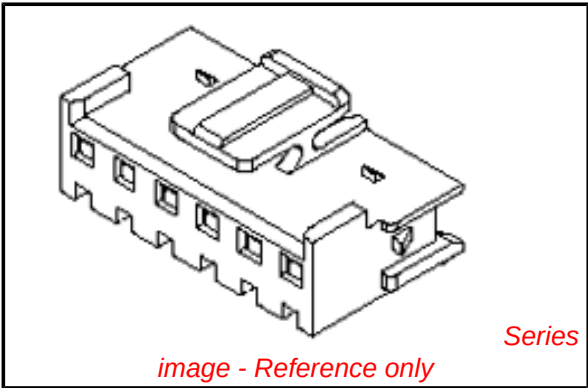

**EU RoHS**

**ELV and RoHS  
Compliant**  
**REACH SVHC**  
**Contains SVHC: No**  
**Low-Halogen Status**  
**Low-Halogen**

**China RoHS**



**Need more information on product  
environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
For a multiple part number RoHS Certificate of  
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any  
non-product compliance questions.

**Search Parts in this Series**

[49517Series](#)

**Mates With**

[35978](#) Header

**Use With**

[359229002](#) Wire-to-Board Terminal. [49518](#)  
TPA™

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION