



OA205AN Series - All Metal

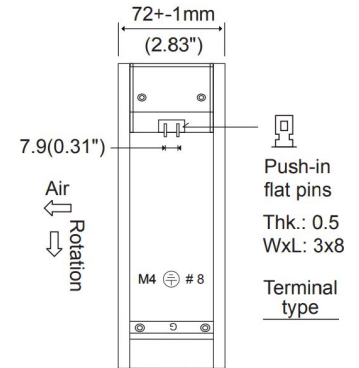

AC Fan - 115V, 230V
205x205x72mm (8.0"x8.0"x2.8")

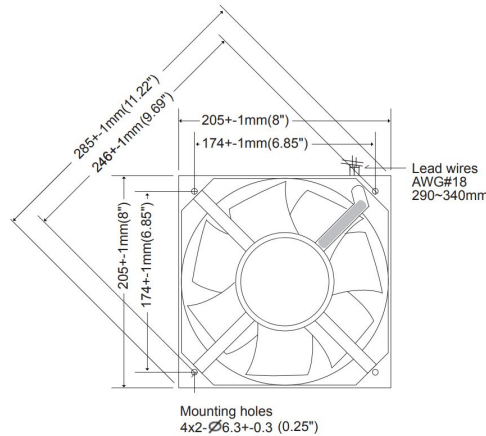

Frame	Die Cast Aluminum	Operating Temperature -30°C ~ +80°C	
Impeller	Metal Alloy	Storage Temperature -40°C ~ +100°C	
Connection	2x Lead Wires, 18 AWG or Terminals	Life Expectancy 50,000 hours (L10 at 55°C)	
Motor	AC Capacitor Inductance, Thermally Protected, IP56 Rated	Available Options Tachometer Alarm PWM	
Bearing System	Dual Ball Bearings	Weight: 5.18 lbs	
Dielectric Strength	1500VAC/min < 1mA	m0	
Insulation Resistance	>100M ohm between leadwires and frame (500 VDC)		

Part Number	Rated Voltage	Input Power 50/60Hz	Voltage Range 50/60Hz	Rated Speed (RPM) 50/60Hz	Airflow (CFM) 50/60Hz	Noise Level (dB) 50/60Hz	Max. Static Pressure ("H ₂ O) 50/60Hz
OA205AN-11-1 * 1856	115	60/80 W	100~120	2800/3000	520/590	67	0.91/0.86
OA205AN-11-2 * 1856	115	55/65 W	100~120	2300/2250	460/458	58	0.69/0.52
OA205AN-11-3 * 1856	115	20/30 W	100~120	1400/1600	310/330	48	0.38/0.29
OA205AN-22-1 * 1856	230	60/80 W	200~240	2800/3000	520/590	67	0.91/0.86
OA205AN-22-2 * 1856	230	55/65 W	200~240	2300/2250	460/458	58	0.69/0.52
OA205AN-22-3 * 1856	230	20/30 W	200~240	1400/1600	310/330	48	0.38/0.29

* Indicate "TB" for terminal type or "WB" for lead wires

PQ Airflow Data specifications are for 60 Hz operation