


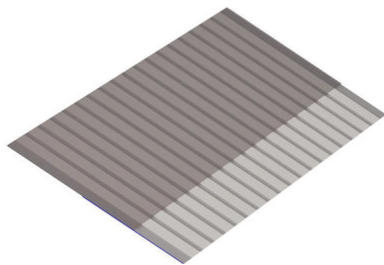

**Part Number :** [152670348](#)  
**Product Description :** 1.00mm Pitch Premo-Flex FFC  
Jumper, Opposite Side Contacts (Type D), 203.00mm  
Cable Length, Tin (Sn) Plating, 18 Circuits  
**Series Number :** 15267  
**Status :** Active  
**Product Category :** Flat-Flexible Cable (FFC)



## Documents & Resources

### Drawings

- [152670348 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

### Specifications

- [PS-15267-001-001.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                                                                              |
|--------------------|--------------------------------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                                                 |
| China RoHS         | <br>per SJ/T 11365-2006 |
| EU ELV             | Not Relevant                                                                                                 |
| Low-Halogen Status | Not Low-Halogen per IEC<br>61249-2-21                                                                        |
| REACH SVHC         | Not Contained per D(2025)4165-DC<br>(25 June 2025)                                                           |
| EU RoHS            | Compliant per EU 2015/863                                                                                    |

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

---

**Part Details**

**General**

|              |                                                                                                                           |
|--------------|---------------------------------------------------------------------------------------------------------------------------|
| Status       | Active                                                                                                                    |
| Category     | Flat-Flexible Cable (FFC)                                                                                                 |
| Series       | 15267                                                                                                                     |
| Description  | 1.00mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 203.00mm Cable Length, Tin (Sn) Plating, 18 Circuits |
| Comments     | Contacts on opposite sides, Type D                                                                                        |
| Product Name | Premo-Flex FFC Jumper                                                                                                     |
| UPC          | 884982443709                                                                                                              |

**Agency**

|    |        |
|----|--------|
| UL | E29179 |
|----|--------|

**Electrical**

|                               |        |
|-------------------------------|--------|
| Current - Maximum per Contact | 1.2A   |
| Voltage - Maximum             | 60V AC |

**Physical**

|                     |                   |
|---------------------|-------------------|
| Cable Length        | 203.00mm          |
| Circuits (Loaded)   | 18                |
| Contact Layout Type | D (opposite side) |
| Design Feature      | Flexible          |
| Flammability        | 94V-0             |

|                               |                 |
|-------------------------------|-----------------|
| Material - Plating Mating     | Tin             |
| Net Weight                    | 2.688/g         |
| Packaging Type                | Bag             |
| Pitch - Mating Interface      | 1.00mm          |
| Temperature Range - Operating | -40° to +105°C  |
| Termination Style             | FFC Connector   |
| Wire/Cable Type               | Flat Flex Cable |
| Wire Size (AWG)               | N/A             |

## Mates With / Use With

### Mates with Part(s)

| Description                                                                                                                                 | Part Number                      |
|---------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------|
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Right-Angle, Bottom Contact, 3.00mm Height, 18 Circuits, Tin-Bismuth Plating        | <a href="#"><u>522711879</u></a> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Vertical, 5.75mm Height, 18 Circuits, Tin-Bismuth Plating                           | <a href="#"><u>526101871</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, 18 Circuits                                     | <a href="#"><u>528081870</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, with Pick-and-Place Polyimide Tape, 18 Circuits | <a href="#"><u>528081871</u></a> |
| Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Right-Angle, Top Contact, 2.70mm Height, 18 Circuits, Tin-Bismuth Plating           | <a href="#"><u>522071885</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Right-Angle, Non-ZIF, Top Contact Style, 18 Circuits                                 | <a href="#"><u>527931870</u></a> |
| 1.00mm Pitch Easy-On FFC/FPC                                                                                                                |                                  |

|                                                                                                                          |                  |
|--------------------------------------------------------------------------------------------------------------------------|------------------|
| Connector, Vertical, Surface Mount<br>Compatible, Non-ZIF, Kinked PC<br>Tails, 18 Circuits                               | <u>528061810</u> |
| 1.00mm Pitch Easy-On FFC/FPC<br>Connector, Right-Angle, Non-ZIF,<br>Top Contact Style Receptacle, 18<br>Circuits         | <u>528071810</u> |
| 1.00mm Pitch Easy-On FFC/FPC<br>Connector, Surface Mount, Right-<br>Angle, Non-ZIF, Bottom Contact<br>Style, 18 Circuits | <u>528521870</u> |

---

This document was generated on Sep 22, 2025