

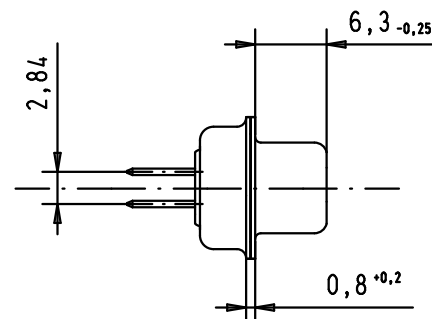


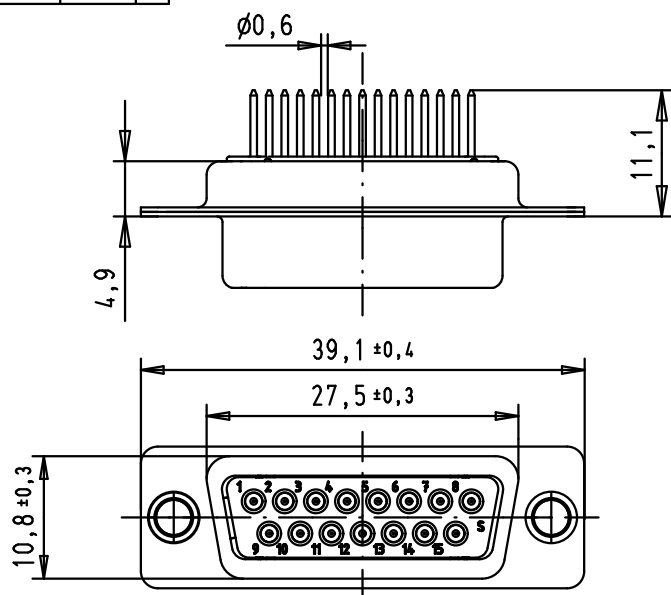

Performance level	PL2
Filter type	C
Capacitance	3900pf±20%
Working Voltage	100v
Current Rating	7.5A
Insulation Resistance	>1GΩ

FREQUENCY (MHz)	ATTENUATION (dB)
5	6dB
10	11dB
50	25dB
100	35dB
500	35dB
1000	32dB

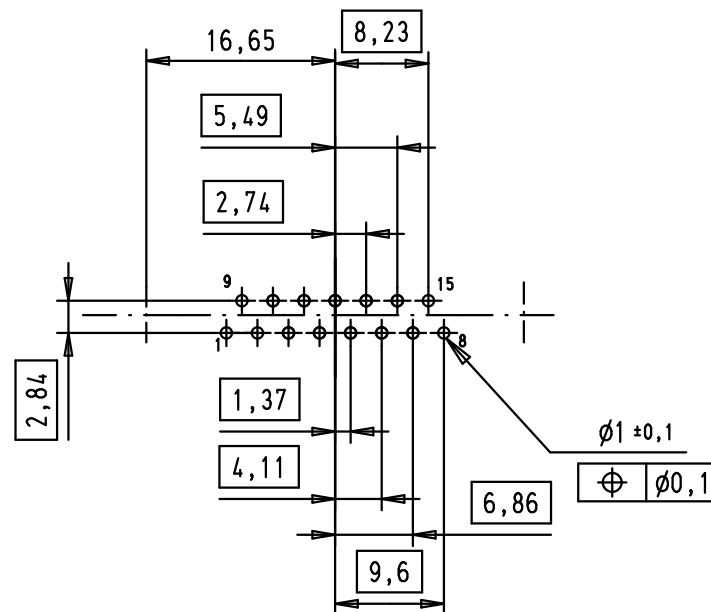

				Dat.	Name		D-Sub, female, straight, 15 Poles, turned solder pins, fixing holes	Ma?stab/ Scale 1.5:1	
			Detail.	8-JUL-02	CV				All Dim. in mm Orig. Size DIN A 4
			Insp.	09/12/11	JB				
36283	09/12/11	SD	Stand.						
33250	03/11/05	JMDR	HARTING EURL F-95972 Paris				TB 09642127240	Blatt/ Page 1 / 1	
31058	8-JUL-02	CV							
Mod.	Dat.	Name							