
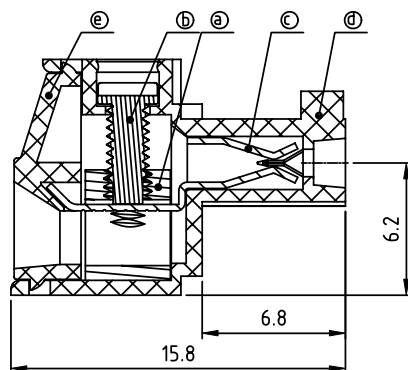
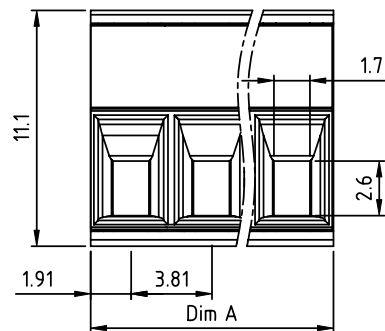


PRODUCT NUMBER	PITCH
TJxx31x300J0G	3.81 mm

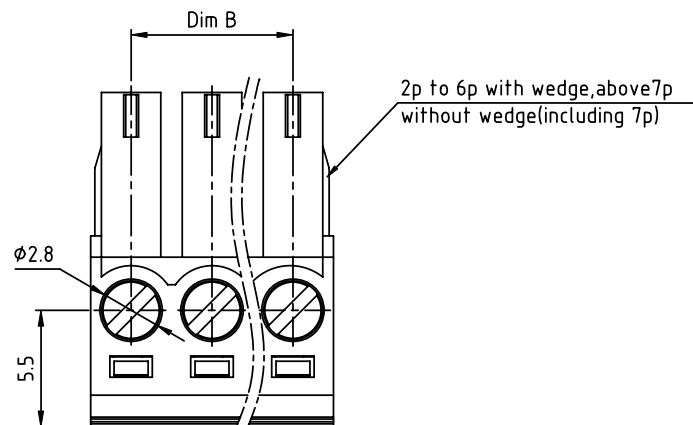

Material

- Item ① Clamp: Brass (CuZn) Ni plated
- Item ② Terminal screw: Steel Zinc plating "-" slot type
- Item ③ Female contact: PhBz, Tin plated
- Item ④ Terminal (housing): Thermoplastic (UL94V-0)
- Item ⑤ Terminal (cover): Thermoplastic (UL94V-0)

Electrical cULus/VDE

- Voltage rating: 300VAC/300VAC
- Current rating: 10A/10.5A
- Wire range: 1.5mm²
- Solid wire (AWG): 16-28
- Stranded wire (AWG): 16-28
- Torque: 3Lb-In/0.2Nm
- Screw: M2
- Wire strip length: 6-7mm
- Withstanding Voltage: 1.6KV/2.5KV
- Operating temperature: -40°C to +115°C
- Safety Approval: cULus VDE

PART NO.: TJ xx 31x 3 00J0 G

N = Number of poles

Dim A = N x 3.81

Dim B = (N-1) x 3.81

Poles	Dim A	Dim B
2-6p	±0.15	±0.15
7-12p	±0.20	±0.20
13-18p	±0.25	±0.25
19-24p	±0.30	±0.30

No. of poles

02 2 poles

03 3 poles

... ..

24 24 poles

Color

0 Black (RAL9005)

2 Red (RAL3001/D)

3 Orange (RAL2011/P)

4 Yellow (RAL1018/A)

5 Green (RAL6018/T)


6 Blue (RAL5015/A)

8 Grey (RAL7035/D)

9 White (RAL1102)

C Green (RAL6018/U)

RoHS compliant
(lead < 4%)
In copper Alloy

mat'l. code				surface ASME Y14.5 ✓	tolerance ASME Y14.5	projection	product family			
ltr	ecn	no	dr	date	tolerances unless otherwise specified		TERMINAL BLOCK			
					angles	X.±0.5	TERMINAL BLOCK PLUGGABLE PLUG, WITHOUT FLANGE			
					0.1	X.X±0.3				
					X*±1"	X.XX±0.1	scale			
					dr	HANKE FENG 031414				
					enr	HANKE FENG 031414				
					chr	SHI JUN 031414				
					appd	SHI JUN 031414				
sheet index	revision	A					type			
	sheet	1					CUSTOMER Drawing			