

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0432028800](#)
Status: **Active**
Overview: [Modular Jacks and Plugs](#)
Description: Modular Jack, Right Angle, Low Profile, Shielded, No Panel Grounding Tabs, without Bottom Grounding Tab, Front Position PCB Ground Tab, 8/10

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Packaging Specification PK-43202-004 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E107635

General


Product Family Modular Jacks/Plugs
Series [43202](#)
Component Type PCB Jack
Magnetic No
Overview [Modular Jacks and Plugs](#)
Performance Category 3
Power over Ethernet (PoE) N/A
Product Name RJ45
UPC 800756071824

Physical

Color - Resin Black
Durability (mating cycles max) 500
Flammability 94V-0
Inverted / Top Latch No
Jack Height 11.81mm
Lightpipes/LEDs None
Material - Metal Brass, Phosphor Bronze
Material - Plating Mating Gold
Material - Plating Termination Tin
Material - Resin High Temperature Thermoplastic
Net Weight 4.393/g
Orientation Right Angle (Side Entry)
PCB Retention Yes
PCB Thickness - Recommended 1.60mm
Packaging Type Tray
Panel Mount Without Flange
Pitch - Mating Interface 1.02mm
Pitch - Termination Interface 1.27mm
Plating min - Mating 1.270µm
Plating min - Termination 2.540µm
Ports 1
Positions / Loaded Contacts 8/10
Surface Mount Compatible (SMC) Yes
Temperature Range - Operating -40°C to +85°C
Termination Interface: Style Through Hole
Wire/Cable Type N/A

Electrical

Current - Maximum per Contact 1.5A
Grounding to PCB Yes
Grounding to Panel None

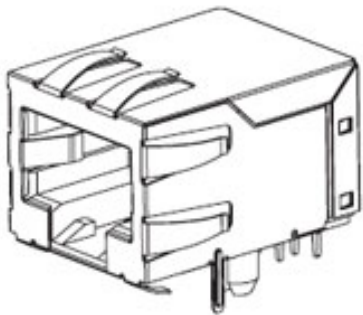

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any
non-product compliance questions.

China ROHS
ELV

Green Image
Not Relevant

Search Parts in this Series

[43202](#) Series

Mates With

FCC 68 Plugs

Shielded	Yes
Voltage - Maximum	125V
Solder Process Data	
Lead-freeProcess Capability	WAVE
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-43202-004
Sales Drawing	SDA-43202

This document was generated on 07/11/2016

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION