


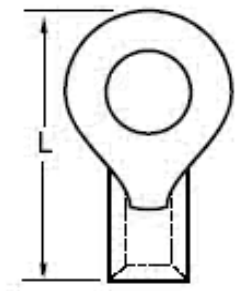

**Part Number :** [191930198](#)  
**Product Description :** VersaKrimp Ring Tongue  
Terminal for 8 AWG Wire, Closed-Brazed Barrel, Stud  
Size 6 (M3.5), Carton  
**Series Number :** 19193  
**Status :** Active  
**Product Category :** Ring and Spade Terminals  
**Engineering Number :** D-356-06



## Documents & Resources

### Drawings

[191930198 sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)


[Creo](#)

### Specifications

[PS-19902-013-001.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Compliant with Exemption 44
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

## Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## Substances of Interest

- PFAS

## EU RoHS Certificate of Compliance

## Additional Product Compliance Information

---

## Part Details

### General

Status	Active
Category	Ring and Spade Terminals
Series	19193
Description	VersaKrimp Ring Tongue Terminal for 8 AWG Wire, Closed-Brazed Barrel, Stud Size 6 (M3.5), Carton
Keyword	Ring Terminal, Ring Terminals
Product Name	VersaKrimp
Style	Ring
Type	Ring Terminal, Metric Ring Terminal
UPC	800755050530

### Agency

CSA	LR18689
UL	E32244

### Physical

Barrel Type	Closed - Brazed
Insulation	None
Material - Plating Mating	Tin
Net Weight	2.972/g
Packaging Type	Carton
Stud Size	6 (M3.5)

Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	7.19mm max.
Wire Size (AWG)	8
Wire Size mm <sup>2</sup>	8.36

---

## Application Tooling

### Global

Description	Part Number
Putt Pump Hydraulic Head Crimper, Die Set Required, For Insulated and Non-Insulated Terminals and Splices	<u><a href="#">192860117</a></u>
Die Set (Large) for the HHLS Hydraulic Crimper	<u><a href="#">192900001</a></u>
PremiumGrade Hand Crimp Tool for 8-2 AWG Terminals	<u><a href="#">640013900</a></u>
RHT1080 Hand Crimp Tool	<u><a href="#">640034400</a></u>
Square "DIN" style dies for 8 AWG	<u><a href="#">640037670</a></u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u><a href="#">640074400</a></u>
Putt Pump Dieless Head Crimper, For Insulated and Non-Insulated Terminals and Splices	<u><a href="#">638162000</a></u>

---

This document was generated on Sep 11, 2025