


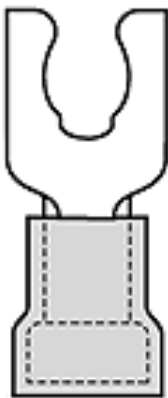

**Part Number :** [191150015](#)  
**Product Description :** Avikrimp Snap Spade  
Terminal for 22-18 AWG Wire, Tape and Reel,  
Stud Size 10 (M5)  
**Series Number :** 19115  
**Status :** Active  
**Product Category :** Ring and Spade Terminals  
**Engineering Number :** AA-8715-10T



## Documents & Resources


**Drawings**  
[191150015\\_sd.pdf](#)

**3D Models and Design Files**  
[191150015\\_stp.zip](#)

**Specifications**  
[PS-19902-011-001.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

Status	Active
Category	Ring and Spade Terminals
Series	19115
Description	Avikrimp Snap Spade Terminal for 22-18 AWG Wire, Tape and Reel, Stud Size 10 (M5)
Keyword	Spade Terminal, Spade Terminals
Product Name	Avikrimp
Type	Spade Snap
UPC	800753091979

#### Agency

CSA	LR18689
UL	E32244

#### Physical

Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	0.853/g
Packaging Type	Adhesive Tape on Reel
Plating min - Mating	4.064µm
Plating min - Termination	4.064µm
Stud Size	10 (M5)
Wire Size (AWG)	18, 20, 22

---

# Application Tooling

## Global

Description	Part Number
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<u>192880023</u>
Mini-Mac Pneumatic Applicator for Ring and Spade Terminals, 22-18 AWG	<u>638851300</u>

---

This document was generated on Mar 03, 2025