


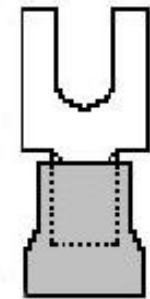

Part Number : [191310006](#)
Product Description : InsulKrimp Block Spade
Tongue Terminal for 12-10 AWG Wire, Stud Size 6
(M3.5), Length 27.31mm
Series Number : 19131
Status : Active
Product Category : Ring and Spade Terminals
Engineering Number : C-2105-06X



Documents & Resources

Drawings

[191310006 sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)
[SOLIDWORKS](#)
[Creo](#)

Specifications

[PS-19902-013-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant with Exemption 44
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC

- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19131
Description	InsulKrimp Block Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 6 (M3.5), Length 27.31mm
Keyword	Spade Terminal, Spade Terminals
Product Name	InsulKrimp
Style	Spade Block
Type	Spade Connector, Metric Spade Connector
UPC	800753101296

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin

Net Weight	1.891/g
Packaging Type	Bag
Plating min - Mating	0.305µm
Plating min - Termination	0.305µm
Stud Size	5-6 (M3-3.5)
Termination Interface Style	Crimp or Compression
Wire Insulation Diameter	6.40mm max.
Wire Size (AWG)	10, 12
Wire Size mm ²	3.30-5.00

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Application Tooling

Global

Description	Part Number
PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 22-10 AWG and 6.0-0.5mm ² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	<u>640010100</u>
PremiumGrade Hand Crimp Tool for Insulkrimp Terminals and Splices, 22-10 AWG (Rings, Spades, Hooks, Block Spades and Flanged Spades)	<u>640010300</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640050100</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640050300</u>
ServiceGrade Hand Crimp Tool for Field Repair only, for production use our PremiumGrade Tool	<u>640160036</u>