


Search within category

GO

BUY NOW

DESIGN / INSTALL

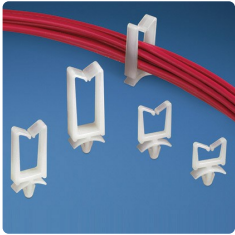

VWS3775-M

Vertical wire saddle, .37" x .75" (9.398mm x 19.05mm) bundle, natural, bulk package.

Specs

Packaging Details

Documents

★ Add to Favorites

🛒 Add to BOM

Material	Nylon 6.6
Mount Method	Push Barb
Overall Width (In.)	0.56
Overall Width (mm)	14.2
Overall Height (In.)	1.17
Overall Height (mm)	29.8
Environment	Indoor
Color	Natural
Flammability Rating	UL94V-2
Max. Bundle Capacity (In.)	0.37 X 1.17
Max. Bundle Capacity (mm)	9.3 X 19.0
Maximum Panel Thickness (In.)	0.04
Maximum Panel Thickness (mm)	1.0
Panel Hole Diameter (In.)	0.19
Panel Hole Diameter (mm)	4.7
UL Recognized	E136577
RoHS Compliancy Status	Compliant
Min. Order Qty.	1,000