
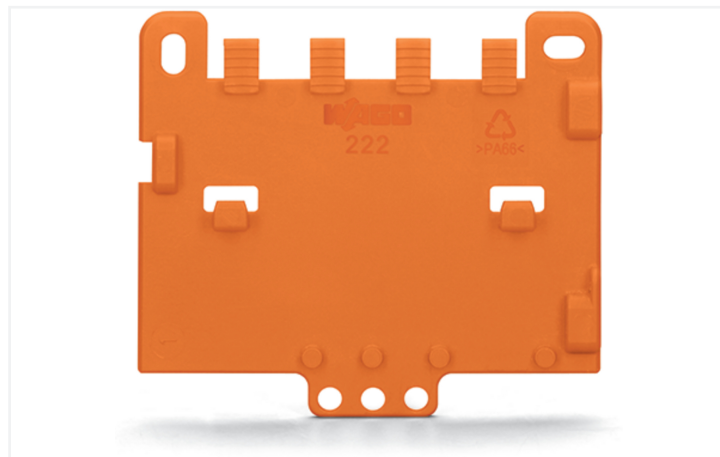


Data Sheet | Item Number: 222-505

Strain relief plate; for mounting carrier; 221 or 222 Series, can be snapped

<https://www.wago.com/222-505>

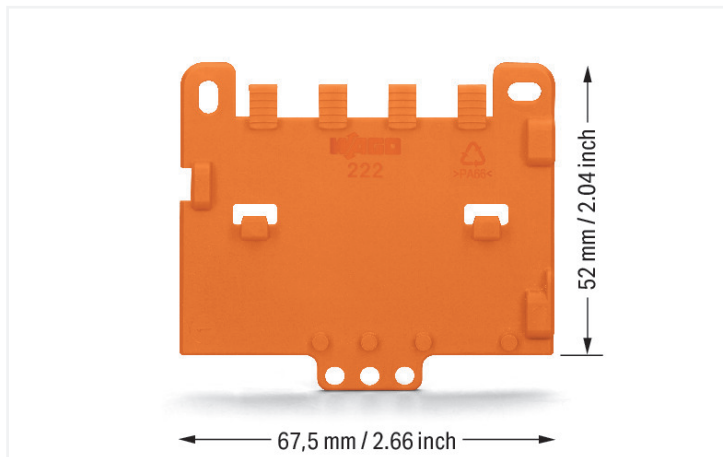

Physical data

Width	4 mm / 0.157 inches
Height	67 mm / 2.638 inches
Depth from upper-edge of DIN-rail	52 mm / 2.047 inches
Depth	58 mm / 2.283 inches

Mechanical data

Suitable	for mounting carriers (221 and 222 Series)
----------	--

Material data

Note (material data)	Information on material specifications can be found here
Fire load	0.151 MJ
Weight	5.6 g

Commercial data

Product Group	7 (Push Wire Conn.)
PU (SPU)	50 (10) pcs
Packaging type	Box
Country of origin	DE
GTIN	4045454714789
Customs tariff number	85389099990



Product Classification	
UNSPSC	39121702
eCl@ss 10.0	27-14-11-92
eCl@ss 9.0	27-14-11-92
ETIM 9.0	EC002848
ETIM 10.0	EC002848
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

Downloads

Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 222-505	↓

Documentation

Bid Text			
222-505	19.02.2019	xml 2.69 KB	↓
222-505	19.05.2017	doc 23.50 KB	↓

CAD/CAE-Data

CAD data	
2D/3D Models 222-505	↓

CAE data	
EPLAN Data Portal 222-505	↓
WSCAD Universe 222-505	↓
ZUKEN Portal 222-505	↓

1 Compatible Products

1.1 Optional Accessories

1.1.1 Mounting adapter

1.1.1.1 Mounting accessories




Item No.: 221-500

Mounting carrier; 221 Series - 4 mm²; for DIN-35 rail mounting/screw mounting; orange


Item No.: 222-500

Mounting carrier; 222 Series; for DIN-35 rail mounting/screw mounting; orange

Installation Notes

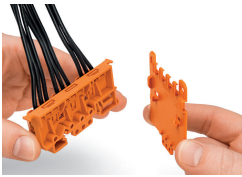

Securing a strain relief plate (222-505) to the mounting carrier.

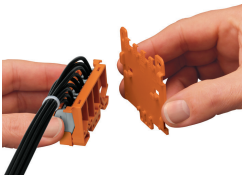

Securing a strain relief plate (222-505) to the mounting carrier.