


Specification Sheet

Part Number: 151-00932

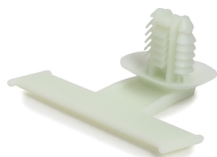

Clip can be installed by hand – no need for hardware or tools.

Design provides low insertion and high extraction force, for simple, secure performance.

Clip keeps bundle away from areas that could cause damage due to rubbing.

Standoff Bundling Clip, 1.97" Long, 0.02 - 0.27" Panel Thickness, PA66HIRHS, Natural, 3000/carton

Article Number 151-00932

Type SOC11FTOVAL

Color Natural (NA)

Quantity Per pack

Product Description Standoff bundling clips provide a straightforward way to secure cable bundles, hoses or pipes. The bundle fastens to the tape bar using tape or cable ties. Multiple orientations allow tape clips to be used with a wide range of panel thicknesses and hole diameters. Standoff keeps bundles away from mounting area to prevent them from damage due to rubbing.

Short Description Standoff Bundling Clip, 1.97" Long, 0.02 - 0.27" Panel Thickness, PA66HIRHS, Natural, 3000/carton

Global Part Name SOC11FTOVAL-PA66HIRHS-NA

Length L (Imperial) 1.97

Length L (Metric) 50.0

Offset Length (Imperial) 0.79

Offset Length (Metric) 20.0

Fixation Method Fir Tree for oval holes

Width W (Imperial) 0.37

Width W (Metric) 9.5

Height H (Imperial) 0.79

Height H (Metric) 20.1

Panel Thickness Min (Imperial) 0.02

Panel Thickness Max (Imperial) 0.27

Panel Thickness Min (Metric) 0.6

Panel Thickness Max (Metric) 6.75

Mounting Hole Diameter D (Imperial) 0.27 x 0.47 " 0.24 x 0.48 " 0.25 x 0.50 "

Mounting Hole Diameter D (Metric) 6.2 x 12.2 mm 6.5 x 13.0 mm 6.5 x 12.5 mm 7.0 x 12.0 mm

Mounting Hole Diameter D Min (Imperial) 0.24

Mounting Hole Diameter D Max (Imperial) 0.50

Mounting Hole Diameter D Max (Metric) 13.0

Material Polyamide 6.6, high impact modified, heat stabilized (PA66HIRHS)

Material Shortcut PA66HIRHS

Flammability UL 94 HB

Halogen Free Yes

UV Resistant (Yes/No) No

Use Conditions For Indoor Use Only

Operating Temperature -40°F to +221°F (-40°C to +105°C)

Operating Temperature intermittent, 1000 hours +320°F (+160°C)

Operating Temperature intermittent, 5000 hours +257°F (+125°C)

Operating Temperature intermittent, 500 hours +329°F (+165°C)

Reach Compliant (Article 33) Yes

ROHS Compliant Yes

Package Quantity (Imperial)	3000
Package Quantity (Metric)	3000
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Privacy Policy](#) [Cookie Policy](#) [Terms and Conditions](#)