


Data Sheet | Item Number: 793-454

WMB marking card; as card; MARKED; U11 - U20 (10x); not stretchable; Horizontal marking; snap-on type; white

<https://www.wago.com/793-454>

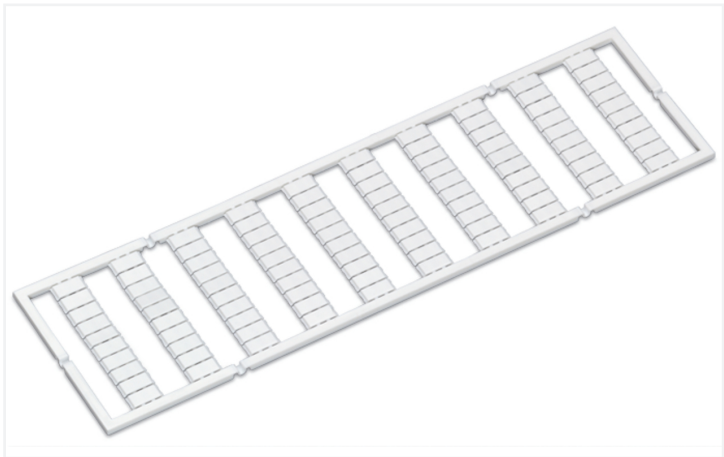

Color: white

Similar to illustration

Technical data		
Marking method		Thermal transfer
Marking		U11 - U20
Marking (number)		10
Marking direction		Horizontal marking
Marking color		black
Marking type		Symbol
Marking layout		Consecutive symbols each strip
Delivery form		Marker card
Delivery form configuration		10 strips with 10 markers per card
Flammability class per UL94		V2

Physical data		
Marker/strip width		5 mm
Marker width		5 mm

Mechanical data		
Smear resistance		EN 60998-1:2004



Material data	
Color	white
UV resistance	EN 60068-2-5:2010 Procedure B
Halogen-free	Yes
Weight	8.8 g
Fire load	0.264 MJ

Commercial data	
Product Group	2 (Terminal Block Accessories)
PU (SPU)	50 (5) pcs
Packaging type	Box
Country of origin	DE
GTIN	4017332696227
Customs tariff number	49119900000

Product Classification	
UNSPSC	55121718
eCl@ss 10.0	27-14-11-37
eCl@ss 9.0	27-14-11-37
ETIM 9.0	EC000761
ETIM 10.0	EC000761
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

Downloads

Environmental Product Compliance


Compliance Search

Environmental Product Compliance 793-454

↓

Installation Notes

Application

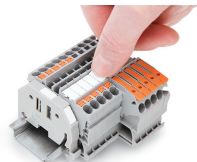

- Separating a strip from the WMB or WMB marker card.
- Stretching a WMB marker strip.
- Separating an individual marker from the WMB marker strip – for larger terminal blocks.
- Snapping a marking strip into the marker slot.

Marking



Snapping a WMB marker strip into the marker slot of the double marker carrier.

Snapping a marking strip into the marker slot.