




Specifications:



Contact rating:	5 V DC, 10 mA
Insulation resistance:	> 100 MΩ
Dielectric strength:	250 V, 50 Hz for the duration of 1 minute
Operating temperature:	−25 °C to +70 °C
Mechanical life:	minimum 10 000 operations
Contacts:	phosphor bronze, gold-plated
Terminals:	PC terminals
Material:	case: PBT black; frame: steel, tin-plated; rotor: PA
Mounting:	on pc-board or single hole mounting, bushing M 7 x 0.75, key 11 mm
Soldering conditions:	wave-soldering – max.: 5 sec, 250 °C ± 5 °C

Models:

MRP 1 – 20

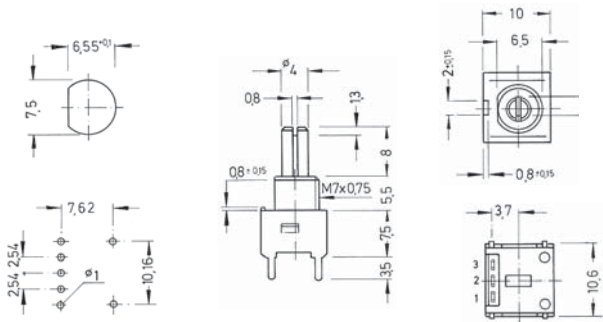

MRP 1 – 20 – R

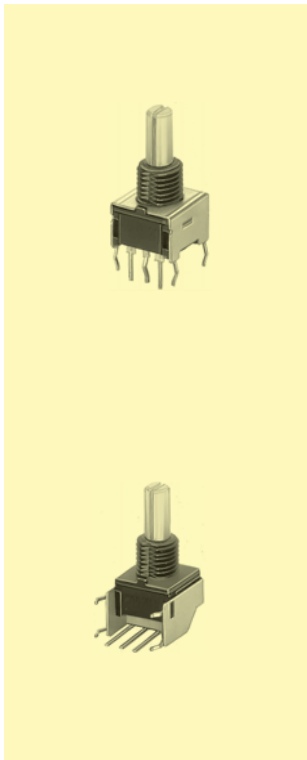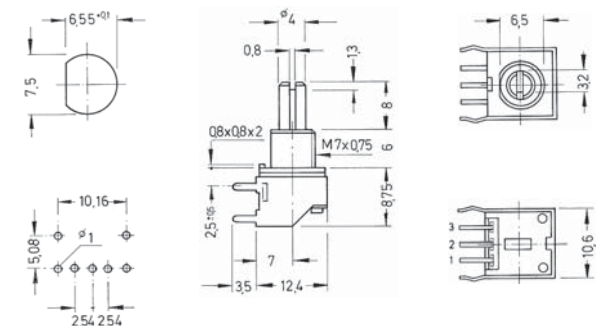

Mounting set for single hole mounting  
1 nut M 7 x 0.75, key 11 mm  
1 washer Ø 12 mm

Order number  
RR 775

Circuit diagram – 20 pulses/circle ± 2 pulses

Contact behaves pulse	Angle					
	0	18°	36°	324°	342°	360°
2-1 on						
2-1 off						
2-3 on						
2-3 off						